

IB IL 24 PWR IN/F-PAC

Order No.: 2861438



<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2861438>

Inline power terminal block, complete with accessories (connector and labeling field), 24 V DC, with fuse (Main voltage)



Commercial data	
EAN	4017918894368
Pack	1 Pcs.
Customs tariff	85389091
Weight/Piece	0.08356 KG

Product notes

WEEE/RoHS-compliant since:
01/18/2007



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Interfaces	
Type of connection	8-pos. Inline power connector
Interface	Supply voltage
Power supply	
I/O voltage	24 V DC

Peripherals voltage range	19.2 V DC ... 30 V DC
Max. current consumption	6 A (8 A)
Fuse	SI 5 x 20 6, 300 AT (in scope of delivery)

General data

Name of protection	Polarity protection, surge protection
Weight	44 g
Number of connectors	1
Width	12.2 mm
Height	119.8 mm
Depth	71.5 mm

Certificates / Approvals

Approval logo



requested approbations

Certification	CUL, GOST, UL
Certification Ex:	CUL-EX LIS, UL-EX LIS

Accessories


Item	Designation	Description
------	-------------	-------------

Marking


0809492	ESL 62X10	Insert strip for laser printer, lettering field: 62 x 10 mm
---------	-----------	---

Drawings

Connection diagram

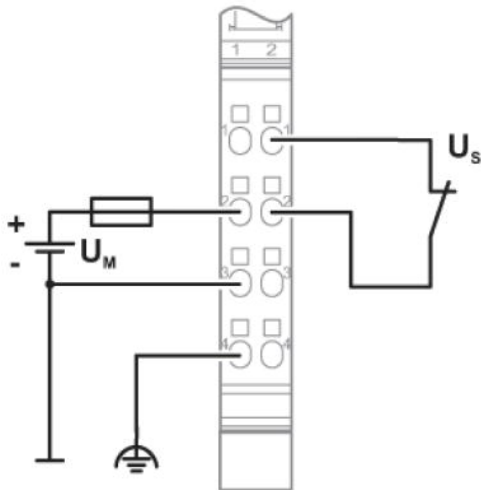

Block diagram

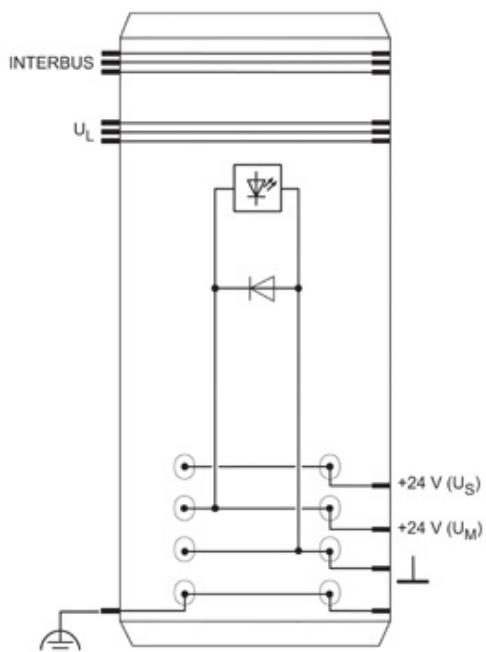

Dimensioned drawing

