

ToLEDo Ball

ToLEDo Ball Dim Frosted 250LM E14 SL

0026942



Range features

- Up to 80% energy saving compared to incandescent lamps
- Instant light
- Suitable for replacement for 25W and 40W incandescent lamps
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs



PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026942
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	E14
Type	ToLEDo Ball
EAN code	5410288269429
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Watt (Nominal) (W)	4.5
Equivalent watt (W)	25
Voltage (V)	220-240

ToLEDo Ball

ToLEDo Ball Dim Frosted 250LM E14 SL

0026942

DATA TABLE

General data

Ordering number	0026942
Dry applications use only	Yes
Technology	LED
Energy saving lamp	Yes
Energy class	A+
Average life (Rated) (h)	25000
Average life (Nominal) (h)	25000
Lamp finish	Frosted
Lamp shape	Ball
Dimmable	Yes
Cap/Base	E14
Type	ToLEDo Ball
EAN code	5410288269429
E-number FI	4740198
Long description	Up to 80% energy saving compared to incandescent lamps. Instant light. Suitable for replacement for 25W and 40W incandescent lamps. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
Product name	ToLEDo Ball Dim Frosted 250LM E14 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	250

ToLEDo Ball

ToLEDo Ball Dim Frosted 250LM E14 SL

0026942

Electrical data

kWh per 1000 hours burning time	5
Equivalent watt (W)	25
Watt (Rated) (W)	4.5
Watt (Nominal) (W)	4.5
Voltage (V)	220-240
Current (A)	0.024
Lamp power factor	0.55

Physical data


Weight (kg)	0.06
Lamp Length (mm) - C/L	89
Max. Lamp Diameter (mm) - D	45
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	10.20 x 4.80 x 4.80
Inner package dimensions (L x W x H) (cm)	15.50 x 10.50 x 11.70
Inner package net weight (kg)	0.33
Outer package dimensions (L x W x H) (cm)	55.00 x 32.60 x 13.70

ToLEDo Ball

ToLEDo Ball Dim Frosted 250LM E14 SL

0026942

TECHNICAL DRAWINGS

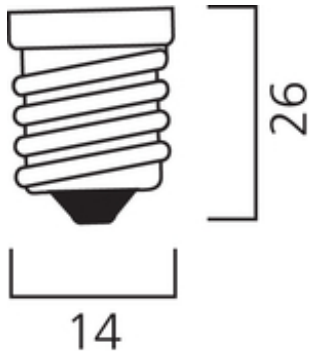

ENERGY LABEL

□