

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

130006-1353

Status:

Active

Overview:

Brad® Mini-Change® Connectors

Description:

Mini-Change® A-Size Single-Ended Cordset, 5 Poles, Female (90°) to Pigtail, 16 AWG, PVC Cable, 3.66m (12.0') Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR6837

UL

E152210

General

Product Family

Industrial Cordsets

Series

130006

Connector End A

Mini-Change®

Connector End B

Pigtail

IP Rating

IP67

Overview

Brad® Mini-Change® Connectors

Product Name

Mini-Change®

Protocol

N/A

Region

America

Type

Single Ended

UPC

78678843293

Physical

Cable Diameter

12.70mm (.500")

Cable Length

3.66m (12.0')

Color - Cable Jacket

Yellow

Coupling Style

Threaded

Gender

Female-Pigtail

Keyway

Single

LED Indicator

No

Material - Cable Jacket

PVC

Material - Connector Body

PVC

Material - Contact

Copper Alloy

Material - Coupling Nut

Black Epoxy Coated Zinc

Material - Plating Mating

Gold

Orientation

90° to Straight

Poles

5

Temperature Range - Operating

-20°C to +105°C

Wire Size AWG

16

Wire/Cable Type

STOOW

Electrical

Current - Maximum per Contact

8A

Voltage - Maximum

600V

Material Info


Old Part Number

105001A01F120

Reference - Drawing Numbers

Sales Drawing

SD-130006-017

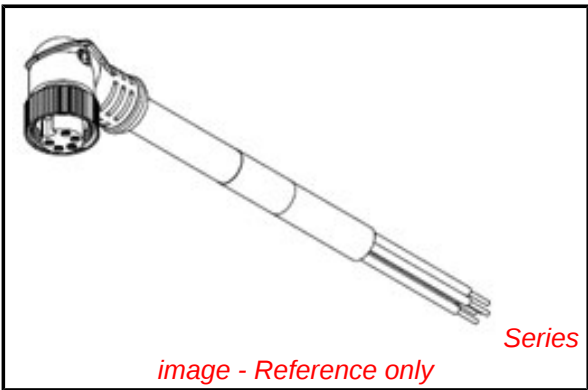

EU RoHS

RoHS Compliant by Exemption

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130006Series

This document was generated on 10/08/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION