

FO patch cable - VS-PC-2XGOF-50-SCRJ/SCRJ-5 - 1654390


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Assembled fiber optic cable, break-out cable, fiberglass multi-mode 50/125 μm , SCRJ/IP20 on SCRJ/IP20, for installation inside control cabinets, length: 5 m



Key commercial data

Packing unit	1 pc
GTIN	 4 017918 970673
Weight per Piece (excluding packing)	100.7 g
Custom tariff number	85447000
Country of origin	Switzerland

Technical data

Mechanical characteristics

Number of positions	2
Connection profile	SCRJ according to DIN EN 50377-6-1
Fiber	50/125 μm
Number of fibers	2.00
Type of cable	Break-out cable
Length of cable	5 m

Ambient conditions

Ambient temperature (operation)	-5 °C ... 70 °C
Degree of protection	IP20

Material data

Housing material	PBT
Outer sheath, material	LSZH
External sheath, color	orange
Ferrule holder color	White

FO patch cable - VS-PC-2XGOF-50-SCRJ/SCRJ-5 - 1654390

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27061003
eCl@ss 7.0	27061003
eCl@ss 8.0	27061003

ETIM


ETIM 2.0	EC000764
ETIM 3.0	EC001263
ETIM 4.0	EC001263
ETIM 5.0	EC000830

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Drawings

Dimensioned drawing

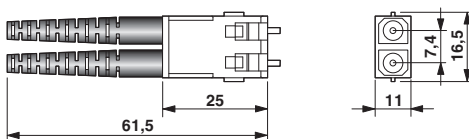

SCRJ connector IP20