


Price* : 9.70 GBP

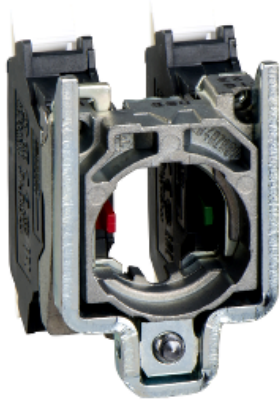

Main

Range of product	Harmony XB4
Product or component type	Complete body/contact assembly
Device short name	ZB4
Fixing collar material	Zamak
Sale per indivisible quantity	1
Head type	Standard
Contacts type and composition	1 NO + 2 NC
Contact operation	Slow-break
Contact block type	Single
Device composition	Fixing collar Contact block

Complementary

CAD overall width	30 mm
Product weight	0.064 kg
Mechanical durability	10000000 cycles
Contacts material	Silver alloy (Ag/Ni)
[Ie] rated operational current	10 A, Q600 10 A, A600
Electrical durability	10000000 cycles, 10 A
Customizable	No
Compatibility code	ZB4

Environment

Protective treatment	TH
Ambient air temperature for storage	-40...70 °C
Ambient air temperature for operation	-40...70 °C
IP degree of protection	IP20 conforming to IEC 60529