



Datasheet

Stock No: 748-2109

ENGLISH

RS Pro Green/Yellow Equipment Wire, 1 mm² CSA, 1500 V 6 A 17 AWG, 500m




BS 4808

Cable Construction

Conductor	Tinned Copper
square(mm ²)	1.0
Construction	T0.2±0.008×32
Standard Dia.(mm)	1.30
Insulation	PVC
Thickness	0.6
Insulation Dia.(±0.15mm)	2.52 +0.13/-0.12

Design

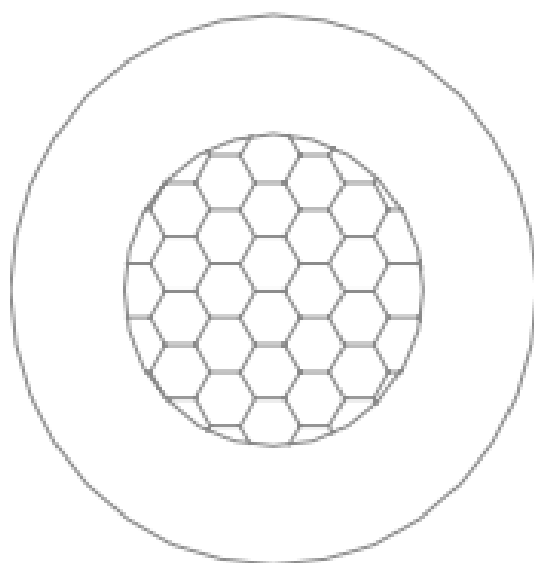

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<18.8
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1500