


# ABP 800-0100

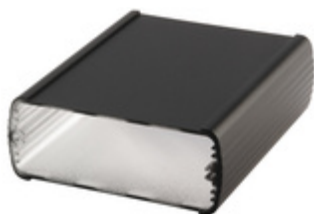

Alubos 800  
Enclosure profiles, closed

Order no.: 84080100

**Colour of enclosure group**

Black, similar to RAL 9005; special colours on request

**Protection class**


ABP, ABPH: up to IP 65/DIN EN 60529; ABPU: IP 40/DIN EN 60529

**Enclosure material**

Extruded profiles: Al Mg Si 0.5 powder-coated; diecast lid: GB Al Si 12, powder-coated; seal: TPE; for details see Technical Information

Scope of delivery: Enclosure profile

Note: C = profile length, special lengths on request.

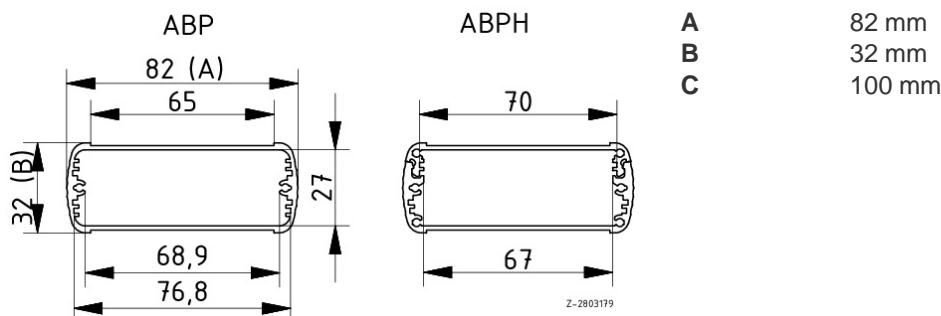

**Technical drawings**

Catalogue drawing in DXF format:  
[84080100\\_ABP-800-0100.dxf](#) (1.1 MB)  
3D product data in STEP format:  
[Registration necessary](#)  
Basic drawing for processing work:  
[84080100\\_ABP-800-100-G.dxf](#) (260 KB)  
Basic drawing for processing work:  
[84080100\\_ABP-800-0100-G.dxf](#) (260 KB)  
Catalogue drawing in PDF format:  
[84080100\\_ABP-800-0100.pdf](#) (106 KB)

**Assembly instructions**

[Alubos-ABPH-....-....pdf](#) (124 KB)  
[Alubos-ABM-....-SAL\(-BE\).pdf](#) (69 KB)  
[Alubos-AB-WL-..pdf](#) (195 KB)  
[Alubos-AB-....-HS.pdf](#) (67 KB)

**Chapter download**

[Alubos\\_GB.pdf](#) (865 KB)



## Accessories



**End cover**

84081000

[ABD 800](#)

For AB 800



**Mounting lid with removable aluminium cap**

84082000

[ABM 800 AL](#)

For AB 800



**Mounting lid with hinged aluminium flap**

84084000

[ABM 800 SAL](#)

For AB 800



**Mounting lid with removable aluminium cap and compartment for 9V block battery**

84082100

[ABM 800 AL BE](#)

For AB 800



**Mounting lid with hinged aluminium flap and compartment for 9V block battery**

84084100

[ABM 800 SAL-BE](#)

For AB 800



**Mounting lid with infrared-permissive plastic cap**

84083000

[ABM 800 IR](#)

For AB 800



**Mounting lid with infrared-permissive plastic cap and compartment for 9V block battery**



84083100 [ABM 800 IR BE](#) For AB 800



**EMC seals**

84200815 [DI 800-EMV](#) For AB 800



**Seals, ultramarine**

84200814 [DI 800-5002](#) For AB 800



**Seals, fire red**

84200811 [DI 800-3000](#) For AB 800



**Seals, rape yellow**

84200812 [DI 800-1021](#) For AB 800



**Seals, patina green**

84200813 [DI 800-6000](#) For AB 800



**Seals UL 94 V0**

84200819\* [DI 800-V0](#) For AB 800



**Wall brackets, sheet steel**



84005000 [AB-WL](#)

For AB 600/800/1000/1300



**Wall brackets, adjustable, sheet steel**

84085000 [AB-800 WL V](#)

For AB 800/820



**Mounting clamps**

84006400 [AB 800 MKL](#)

For AB 800

84006300 [AB-MKL](#)

For AB 600/800/1000



**Self-adhesive rubber feet, black**

84006700 [AB - GF](#)

Polyurethane, 65-75 Shore Black

\* = Available on request