


Deep groove ball bearings, single row, unsealed



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
12	37	12	10,1	4,15	0,176	45000	28000	0,060	6301 *

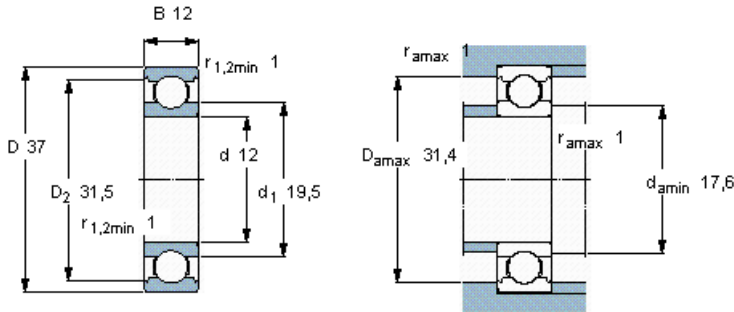

Calculation factors

k_r 0,03
 f_0 11