



MINI PACK

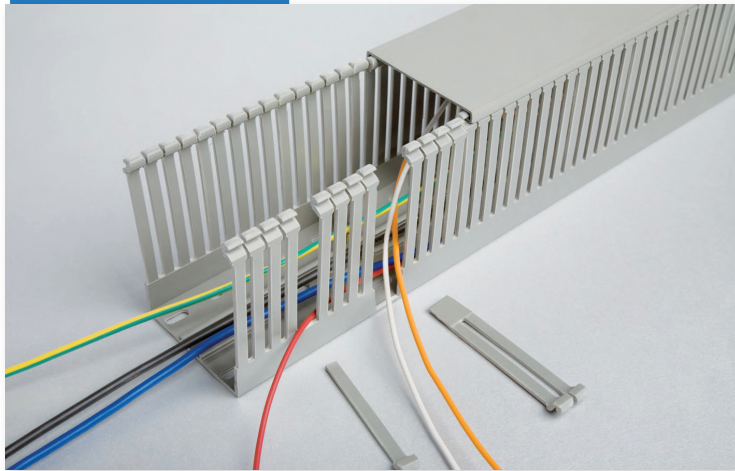


Betaduct PVC metric narrow open slot provides lightweight self-extinguishing cable trunking with excellent rigidity and performance characteristics. Its restricted slot design, enables the wire to be retained in the slot.

Supplied with a lid. Available in 3 sizes. Supplied as 4 x 1 metre lengths

Side Slot Design

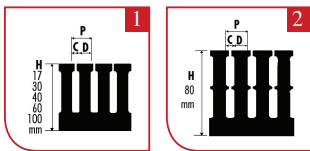

Base Hole Design

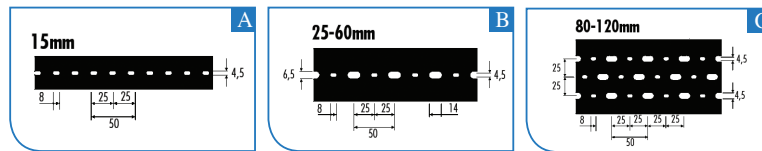

Specification:

Material: Self-extinguishing PVC

Slot Pitch: 20mm

Slot Width: 8mm

Webs: 12mm

Flammability: UL94 V-0 Rated material

Service temperature rating: 15°C to + 60°C

Standards: RoHS 2 compliant, UL94 V-0, A Norme EN50085-2-3, CSA, UR, RINA, CE marked

Part Numbers:

RS PART NO.	BETADUCT PART NO.	EXTERNAL SIZE W X H (mm)	USABLE SECTION (mm ²)	BASE HOLE DESIGN	SIDE SLOT DESIGN	C	D	P	PACK QUANTITY METRES
8781148	10440022	25 x 40	760	B	1	4	6	10	4 x 1m
8781126	10440033	40 x 60	1960	B	1	4	6	10	4 x 1m
8781117	10440034	40 x 80	2680		2	4	6	10	4 x 1m