




ENGLISH

Datasheet

Stock No: 522-682

RS Pro SY Control Cable, 4 Core, Screened Polyvinyl Chloride PVC Sheath

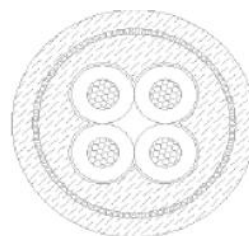

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 24$

Insulation: PVC

Insulation Dia. (mm): $2.34 \pm 0.1 \times 4C$

Filler: Chalk

Jacket 1: PVC

Outer Dia. (mm): 6.55 ± 0.2

Braid Shield: Galvanised Steel

Conductor Dia. (mm): 0.24

Conductor Qty: 24×3

Jacket: Trans PVC

Outer Dia. (mm): 9.63 ± 0.25

Colour:

The colour of the insulation: Blue , Brown ,
Black ,
Yellow/Green

The jacket colour: Transparent

Marking(3times/m):

RS 522682 SY/CC 4 Core x 0.75mm²

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<28.1

Min.Insulation DC Resistance at 20°C ($\text{M}\Omega \cdot \text{KM}$) :
>500

Current Rating : 6 A