


Deep groove ball bearings, single row, shield on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
5	16	5	1,14	0,38	0,016	95000	48000	0,0050	625-2Z *

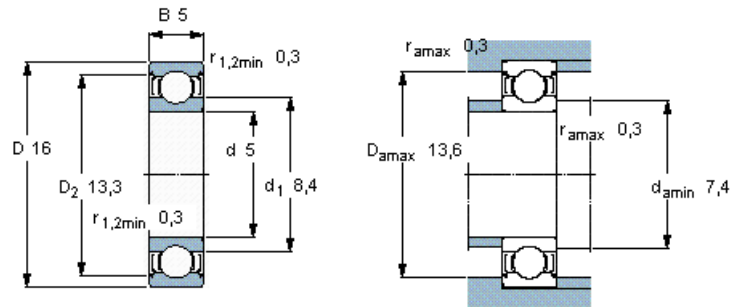

Calculation factors

$k_r = 0,025$
 $f_0 = 8,4$