


Dell 24 Monitor
Model P2414H
23.8" monitor

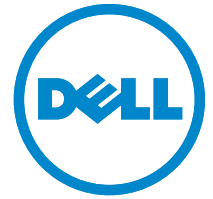

Dell 24 Monitor | P2414H (23.8", 60.47 cm VIS)

Boost productivity with the visually brilliant, eco-efficient Dell 24 Monitor

The Dell 24 Monitor offers you multiple ways to help increase productivity while you work:

- Conveniently connect to a wide range of devices through multiple analog and digital input ports
- Easily adjust the monitor to your viewing preference with flexible viewing options
- See more and do more with impressive screen clarity and an ultra-wide viewing angle
- Enjoy reliable service and support to minimize downtime
- Experience eco-efficient features that help reduce environmental impact and lower energy costs



Dell 24 Monitor | P2414H (23.8", 60.47 cm VIS)

The Dell 24 Monitor | P2414H (23.8", 60.47 cm VIS) offers you:

Flexible viewing and connectivity options

- Designed to help enhance your productivity with full adjustability and panel mounting features, and a wide range of convenient connectivity ports.
 - Enjoy great viewing flexibility with full adjustability features such as tilt, pivot, swivel and a height adjustable stand.
 - Connect easily to peripherals and devices with the convenient and comprehensive range of analog and digital connectivity ports and cables such as VGA, DisplayPort, DVI-D¹ and 4 USB ports.
 - Easily detach the monitor panel from its stand with the Dell Quick Release feature and mount it on the optional Dell Single Monitor Arm or Dell Dual Monitor Stand² for even greater viewing flexibility.
 - The Dell 24 Monitor can also be purchased without a stand when other mounting options are preferred.

Impressive screen clarity

- Get impressive screen clarity with Full HD 1920 x 1080 resolution.
- Experience accurate, consistent colors with the ultra-wide 178° x 178° viewing angle.
- Enjoy excellent image quality including deep blacks, bright whites and outstanding details with the high 2 million:1 Dynamic Contrast Ratio.


Reliability and efficiency you can count on

- Rest assured that Dell's Premium Panel Guarantee³ offers a free panel exchange in the event that you discover even one bright pixel during the Limited Hardware Warranty⁴ period.
- Enjoy peace of mind with Dell's Limited Hardware Warranty⁴ and 3-year Advanced Exchange Service⁵ to minimize your downtime.
- Experience the low power consumption of this monitor (less than .3W in standby mode) that can help you lower energy costs.
- Control power consumption with power management features like PowerNap.
- Environmentally preferable materials make this Dell Monitor easier to recycle.
 - Eco-designed BFR/PVC-free monitor (except external cables) with more than 25% post-consumer recycled plastics in the chassis.
- Minimize your environmental impact with the Dell 24 Monitor, which meets the latest regulatory and environmental standards like ENERGY STAR®, EPEAT® Gold and TCO Certified Displays.

Perfect for:

- Knowledge workers for financial and administrative tasks, sales & marketing presentations and reports
- Task workers for call center monitoring, data entry, sales order input, administration
- Educational institutions for learning modules, classroom activities
- Healthcare organizations for administration, viewing patient records, medical data and charts
- Home office use for work applications, Internet, research, movies

Designed with productivity-boosting features for business and home office.

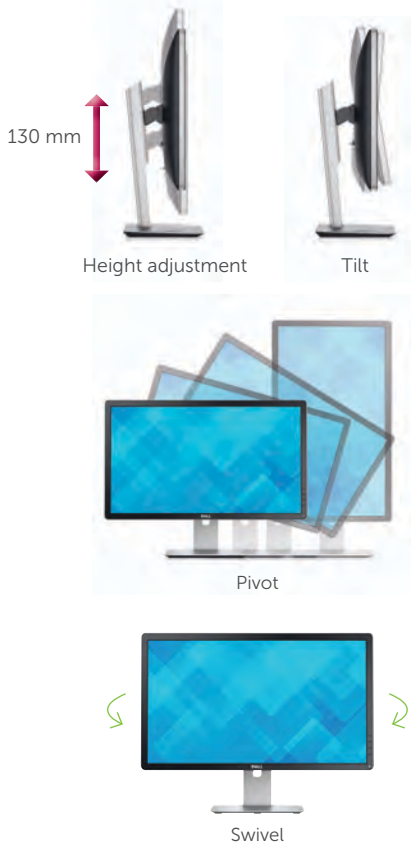

Connectors



- A AC power
- B DisplayPort
- C DVI-D
- D VGA
- E USB upstream
- F USB downstream (4)
- G Stand lock feature

Upgrade to U2412M⁸

Greater resolution (1920 x 1200)

Compare to P2412H

What's in the box?

Monitor, Stand, power cable, VGA cable, DisplayPort cable, USB cable, Quick start guide, drivers and documentations.

Dell recommends that customers dispose used computer hardware, including monitors, in an environmentally sound manner. Potential methods include reuse of parts or whole products and recycling of product, components and/or materials. For more information, please visit http://dell.com/recycling_programs and www.dell.com/environment



Dell 24 Monitor | P2414H (23.8", 60.47 cm VIS)

Display

Model number	P2414H
Viewable image size (diagonal)	60.47 cm (23.8 inches)
Active display area	
Horizontal	527.04 mm (20.75 inches)
Vertical	296.46 mm (11.67 inches)
Maximum resolution	Full HD 1920 x 1080 at 60 Hz
Aspect ratio	16:9
Pixel pitch	0.2745 mm x 0.2745 mm
Brightness (typical)	250 cd/m ²
Color gamut (typical)	86% ⁶
Color depth	16.7 million colors
Contrast ratio (typical)	1000:1
Dynamic contrast ratio (typical)	2 million:1
Viewing angle (typical) (vertical/horizontal)	178° / 178°
Response time (typical)	8 ms (gray to gray)
Panel technology	In-plane switching, anti-glare
Backlight	LED

Connectivity

Connectors	VGA, DVI-D (HDCP), DP, 4 x USB
Dell soundbar ⁷ (optional)	AC511
Remote asset management	Yes, via Dell Display Manager

Design features

Stand	Height adjustable stand, tilt, swivel, pivot and built-in cable management
VESA mounting support (wall mount kit sold separately)	Dell Quick Release feature (100 mm x 100 mm)
Security	Security lock slot and stand lock (security lock and stand screw, M3x6 not included)

Power

AC input voltage/frequency/current	100 to 240 VAC/50 or 60 Hz ±3 Hz/1.2A (typical)
Power consumption (typical)	28W
Power consumption standby/sleep mode	<0.3 W

Dimensions (with stand)

Height (compressed ~ extended)	369 mm (14.53 inches) ~ 499.0 mm (19.65 inches)
Width	565.6 mm (22.27 inches)
Depth	180.0 mm (7.09 inches)

Weight

Weight (panel only – no stand)	3.51 kg (7.72 lb)
Weight (with stand)	5.83 kg (12.83 lb)
Shipping weight	7.79 kg (17.14 lb)

Standard service plan

- 3 years Advanced Exchange Service⁵ & Limited Hardware Warranty⁴

Environmental compliance

ENERGY STAR[®], TCO Certified Displays, EPEAT[®] Gold, China Energy Label, CEL, WEEE, ErP (EuP) Standards, Korea E-Standby

^{*}Registered in US and Canada only.

¹Excluding DVI-D cable.

²Dell Single Monitor Arm and Dual Monitor Stand are sold separately. Dual monitor stand will support panel combinations of up to 27" (68.6 cm) with 19" (48.00 cm) and up to 14.33 lb. (6.5 kg) for each side (left/right panel).

³Even if only one bright pixel is found on our select range of monitors, a free panel exchange is guaranteed during the Limited Hardware Warranty period (see pixel panel info located on dell.com web page for complete details).

⁴<http://support.dell.com/support/topics/global.aspx/support/kcs/document?docid=414288>

⁵For a copy of the Limited Hardware Warranty, write Dell USA LP, Attn: Warranties, One Dell Way, Round Rock, TX 78682 or see dell.com/warranty.

⁶Advanced Exchange Service: Replacement part/unit dispatched, if needed, following completion of phone/online diagnosis. Fee charged for failure to return defective unit. Availability varies. Other conditions apply.

⁷Color gamut (typical) is based on CIE1976 (86%) and CIE1931 (72%) test standards.

⁸Only compatible with AC511 soundbar. Launch date for soundbar varies across countries. Please check with your country sales representatives for more information.

⁹Please check with your sales representative for availability of upgrade product.

Based on Dell document Ad#A13001515 dell.com/monitors

Product availability varies by country. Please contact your Dell representative for more information.