

Flat Cable Connectors SEK

- har-mik®
- D-Sub
- InduCom

Applications



Product details

09 18 510 5803
IDC female connector

Termination	Flat cable insulation displacement
Connector size	10 contacts
IDC strain relief clamp	Without strain relief
Cover	With an open end cover
Centre polarization	With central polarisation
Performance level	AU-0.76•m [30• Inch]
RoHS compliant	Yes

Available Downloads

Title	Format	
Data sheet	PDF	download
CAD data 2D	DXF	download

Further links

3D-Library



Inquiry




5

4


3

2


1

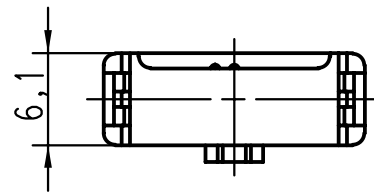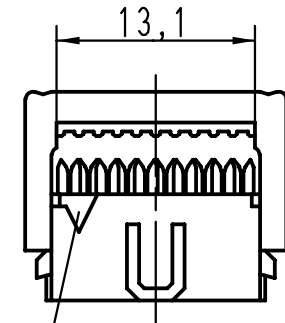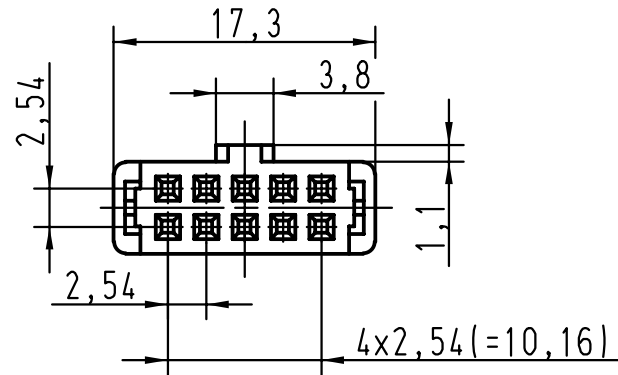

vorverrastet
pre assembled
preassemble

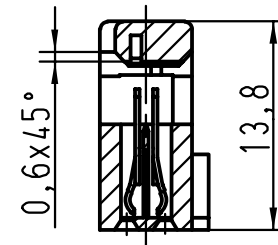

verrastet
fitted
assemble

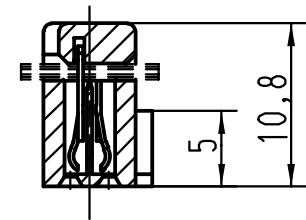

1) Markierung erster Kontakt, Ader 2 des Flachkabels
1) Contact no.1, 1st wire of flat cable
1) Contact no.1, repère 1 du câble



All Dimensions in mm
Original Size DIN A 4

Techn. Character.

Nicht tolerierte Masse/ Free size tolerances

09185105803

0,76 µm Au

09185106803

2

09185107803

3

Bestell-Nr.
Part-No.
Reference

Anforderungsstufe
performance level
Niveau de qualite

27570

01-FEB-00

JB

Mod.

Dat.

Name

HARTING EURL
F-95972 Paris



TB

0918510X803

Sub.

Blatt/ page

1/1

	Dat.	Name	Massstab/Scale
Detail.	01-FEB-00	Th	
Insp.	01-FEB-00	JMV	
Stand.			

2:1

SEK 18 Female connector
10 poles
with central polarisation
cover without cable stop