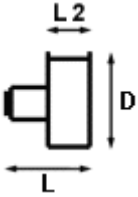












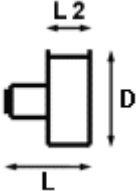


U-Fans

							
Radial Blowers	Dimension DxL2xL	Voltage	Power	Pressure	[l/min]	Life Expect.	Ambient Temp.
	[mm]	[V]	[W]	[Pa]	w.p.	hr	°C
U51 Serie	Ø52x20x52						
U51HM under construction	Ø52x20x52	6	-	-	-	-	-20 / +65
U51HM under construction	Ø52x20x52	12	0.8	280	80	4000	-20 / +65
U64 Serie	Ø64x24x56.5						
U64HM	Ø64x24x56.5	3	2.52	485	152	2000	-20 / +65
U64HM	Ø64x24x56.5	6	1.92	415	145	2500	-20 / +65
U64HM	Ø64x24x56.5	12	1.98	425	146	2500	-20 / +65
U64LM	Ø64x24x56.5	6	0.93	230	110	4000	-20 / +65
U64LM	Ø64x24x56.5	12	0.76	195	102	4000	-20 / +65
U64LM	Ø64x24x56.5	24	0.82	225	108	4000	-20 / +65
U81 Serie	Ø82x24x73						
U81HM under construction	Ø82x24x73	6	-	-	-	-	-20 / +65
U81HM under construction	Ø82x24x73	12	4.5	630	205	9000	-20 / +65
U81HM under construction		24	-	-	-	-	-20 / +65
U97 Serie	Ø98x24x65						
U97LM	Ø98x24x65	5	4	650	206	6000	-20 / +65
U97LM	Ø98x24x65	12	7.4	905	240	9000	-20 / +65
U97EM	Ø98x24x65	24	5.4	725	222	9000	-20 / +65
U97EQ	Ø98x24x65	12	8.4	925	220	30000	-20 / +65
U120 Serie	Ø122x26x83						
U120HM under construction	Ø122x26x83	6	-	-	-	-	-20 / +65

U120HM under construction	Ø122x26x83	24	-	-	-	-	-20 / +65
U150 Serie	Ø154x29x98						
U150HM under construction	Ø154x29x98	6	-	-	-	-	-20 / +65
U150HM under construction	Ø154x29x98	12	17.6	1500	550	12000	-20 / +65
U150HM under construction	Ø154x29x98	24	-	-	-	-	-20 / +65
	Dimension DxL2xL						
		Voltage	Power	Pressure	[l/min]	Life Expect.	Ambient Temp.