

ZBVJ45

red light block for head Ø22 integral LED 12V
spring clamp terminals

Price* : 6.91 GBP



Main

| | |
|-------------------------------|----------------------------|
| Range of product | Harmony XB4 Harmony XB5 |
| Product or component type | Light block |
| Device short name | ZBV |
| Sale per indivisible quantity | 4 |
| Connections - terminals | Spring clamp terminals |
| Signalling type | Steady |
| Light source | Protected LED |
| Bulb base | Integral LED |
| Light block supply | Direct |
| Light source colour | Red |
| [Us] rated supply voltage | 12 V AC/DC, 50/60 Hz |

Complementary

| | |
|-----------------------------|---|
| Product weight | 0.017 kg |
| Supply voltage limits | 10...15 V DC 10.2...13.8 V AC |
| Current consumption | 18 mA |
| Service life | 100000 h at rated voltage and 25 °C |
| Surge withstand | 1 kV conforming to IEC 61000-4-5 |
| Mounting of block | Front mounting |
| Electrical composition code | M1 M2 M3 M4 M5 M6 M10 MF1 P1 P2 PF1 |
| Compatibility code | ZBV |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Environment


| | |
|---------------------------------------|--|
| Protective treatment | TH |
| Ambient air temperature for storage | -40...70 °C |
| Ambient air temperature for operation | -40...70 °C |
| IP degree of protection | IP20 conforming to IEC 60529 |
| Standards | EN/IEC 60947-1 EN/IEC 60947-5-1 EN/IEC 60947-5-4 EN/IEC 60947-5-5 JIS C 4520 UL 508 CSA C22.2 No 14 |
| Resistance to fast transients | 2 kV conforming to IEC 61000-4-4 |
| Resistance to electromagnetic fields | 10 V/m conforming to IEC 61000-4-3 |
| Resistance to electrostatic discharge | 6 kV on contact (on metal parts) conforming to IEC 61000-4-2 8 kV in free air (in insulating parts) conforming to IEC 61000-4-2 |
| Electromagnetic emission | Class B conforming to IEC 55011 |

Contractual warranty

| | |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Dimensions

with ZB5AZ009 Fixing Collar

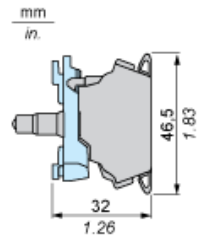

with ZB4BZ009 Fixing Collar

