


INSTRUCTIONS FOR USE

INTERMEDIATE DESIGN

HYD-TUF™ gloves

A. Use

These gloves are designed to protect the hands against light duty mechanical risks. They are in conformity and are marked as per requirements of the European Directive 89/686/EEC and its Amendments and they are in compliance with the European Standards EN 420 and EN 388.

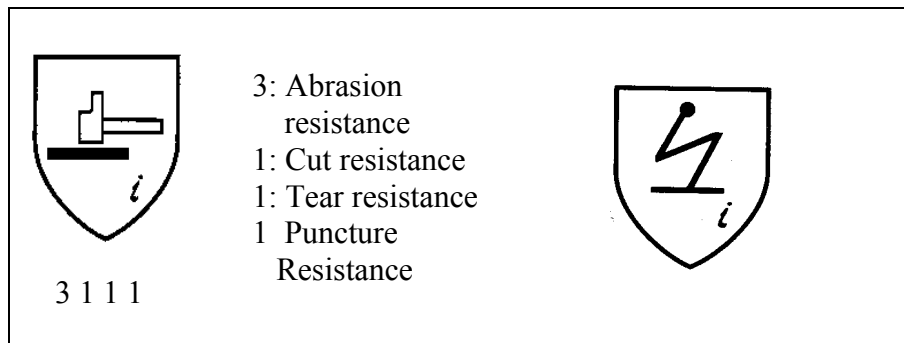

EC-Type examination certificate by ITF France (I.D. 0072) – Avenue Guy De Collongue Ecully.

B. Precautions for use

NEVER USE THESE GLOVES AGAINST CHEMICALS, nor for protection against heavy duty mechanical applications.

Do not use against flames.

Before usage, inspect the gloves for any defects or imperfections. Avoid wearing damaged or worn out gloves.

C. Ingredients / Hazardous ingredients

These gloves do not contain any ingredients which are known to be a possible cause of allergies to sensitised people.

If allergic reactions would occur, obtain medical advice immediately.

For more information, please contact Ansell's Customer service department.

D. Care instructions

Storage : Keep out from direct sunlight; store in a cool and dry place.
Keep out from sources of ozone or ignition.

Cleaning : The gloves can be laundered at 60 °C maximum.

E. Disposal

Used gloves may be contaminated with infectious or other hazardous materials.
Dispose of according to Local Authority Regulations. Landfill or incinerate under controlled conditions.

Ansell Healthcare Europe
Internationale Laan 55
1070 Brussels
Belgium

Type	Style	Reference	Size	Length
Regular	Knitwrist	52-502	9 , 10	310 mm
	Safety cuff	52-507		270 mm
Gun-cut	Knitwrist	52-542		270 mm
	Safety cuff	52-547		280 mm