

ToLEDo+ GLS

ToLEDo+ GLS Dim 7.5W 470LM 827 B22 SL

0026427



Range features

- Long life of up to 30,000 hours; up to 30 times longer than incandescent lamps
- Over 80% energy saving compared to incandescent - Rapid payback on investment
- Homelight 2700K colour temperature - ideal for domestic lighting, restaurants, leisure and hotels
- ToLEDo+ GLS Dimmable provides wide light distribution of 260 degrees
- Instant start - ideal for use on presence detection and in high use areas



PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026427
Average life (Rated) (h)	30000
Energy class	A
Lamp shape	A60
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	B22
Type	ToLEDo+ GLS
EAN code	5410288264271
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	470
Watt (Nominal) (W)	7.5
Equivalent watt (W)	40
Voltage (V)	220-240

ToLEDo+ GLS

ToLEDo+ GLS Dim 7.5W 470LM 827 B22 SL

0026427

DATA TABLE

General data

Dry applications use only	Yes
Ordering number	0026427
Technology	LED
Energy saving lamp	Yes
Average life (Nominal) (h)	30000
Average life (Rated) (h)	30000
Energy class	A
Lamp finish	Frosted
Lamp shape	A60
Dimmable	Yes
Cap/Base	B22
Type	ToLEDo+ GLS
EAN code	5410288264271
Long description	Long life of up to 30,000 hours; up to 30 times longer than incandescent lamps. Over 80% energy saving compared to incandescent - Rapid payback on investment. Homelight 2700K colour temperature - ideal for domestic lighting, restaurants, leisure and hotels. ToLEDo+ GLS Dimmable provides wide light distribution of 260 degrees. Instant start - ideal for use on presence detection and in high use areas
Product name	ToLEDo+ GLS Dim 7.5W 470LM 827 B22 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	>15000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	470
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	470

ToLEDo+ GLS

ToLEDo+ GLS Dim 7.5W 470LM 827 B22 SL

0026427

Electrical data

kWh per 1000 hours burning time	8
Watt (Rated) (W)	7.5
Watt (Nominal) (W)	7.5
Equivalent watt (W)	40
Voltage (V)	220-240
Lamp power factor	0.7

Physical data


Weight (kg)	0.09
Lamp Length (mm) - C/L	108
Max. Lamp Diameter (mm) - D	60
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	11.40 x 6.40 x 6.40
Inner package dimensions (L x W x H) (cm)	20.90 x 14.10 x 14.10
Inner package net weight (kg)	0.54
Outer package dimensions (L x W x H) (cm)	74.80 x 21.70 x 31.80

ToLEDo+ GLS

ToLEDo+ GLS Dim 7.5W 470LM 827 B22 SL

0026427

TECHNICAL DRAWINGS

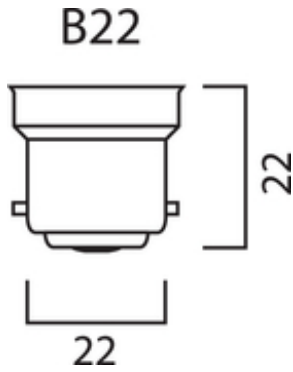

ENERGY LABEL

□