





ENGLISH

Datasheet

Stock No: 522-513

RS Pro 3 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

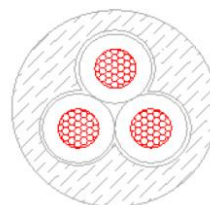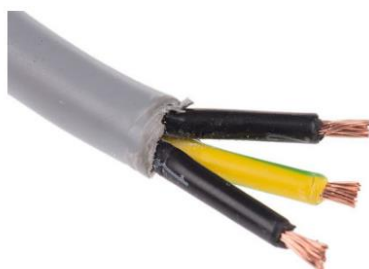

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$

Insulation: PVC

Insulation Dia. (mm): $2.8 \pm 0.1 \times 3C$

Filler: Chalk

Jacket: PVC

Outer Dia. (mm): 7.25 ± 0.25

Colour:

The colour of the insulation: Black x 2 ,
Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking (3 times/m):

RS 522513 YY/NR 3 Core x 1.5mm²

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) :
<13.7

Min. Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 16 A