

## Optional Nozzles

Pistolets en option

Optionale Düsen

Ugelli opzionali

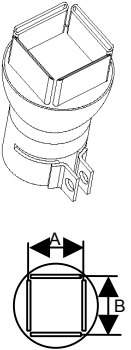
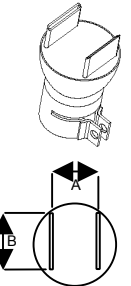
 
Boquillas opcionales

選購的噴嘴

可选喷嘴

ノズル・オプション

노즐 옵션

PLCC, BQFP, QFP	Model	Chip Type	A (mm)	B (mm)
		H-P20	PLCC-20	11.9
H-P28		PLCC-28	14.5	14.5
H-P32		PLCC-32	16.9	14.3
H-P44		PLCC-44	19.5	19.5
H-P52		PLCC-52	22.0	22.1
H-P68		PLCC-68	27.0	27.2
H-P84		PLCC-84	32.4	32.4
H-Q07		QFP-48	8.4	8.4
H-Q10		QFP-44	13.4	13.4
H-Q14		QFP-52,80	17.3	17.3
H-Q1420		QFP-64,80,100	23.4	18.1
H-Q28		QFP-120,128,144,160	31.2	31.2
H-BQ23		BQFP-100	22.4	22.4
H-Q3232		QFP-240	34.5	34.5
H-BQ38		BQFP-196	37.7	37.7
H-Q2626		QFP-208	29.8	29.8
SOIC, TSOP				
	H-S16	SOIC 14,16	6.8	10.2
	H-SL16	SOL 14,16	10.6	10.8
	H-SL20	SOL 20,20J	10.6	13.3
	H-SL24	SOL 24,24J	10.6	15.9
	H-SL28	SOL 28	10.6	18.4
	H-SL44	SOL 44	16.0	27.9
	H-SOJ32	SOJ 32	13.5	20.6
	H-SOJ40	SOJ 40	13.5	25.4
	H-TS24	TSOP 20-24	17.0	7.1
	H-TS32	TSOP 28-32	21.0	9.1
	H-TS40	TSOP 40	21.0	10.8
	H-TS48	TSOP 48	21.0	13.3
	H-TSW24	TSOP 20-24	10.2	18.4
	H-TSW44	TSOP 24-28/40-44	12.7	19.8
CHIP & SOT				
	Model	Ø A (mm)		
	H-D25	2.5		
	H-D50	5.0		
	H-D120	12.0		