


Spherical roller bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min	kg	-	* - SKF Explorer bearing
65	120	38	193	216	24	-	1,60	BS2-2213-2CS/VT143 *	

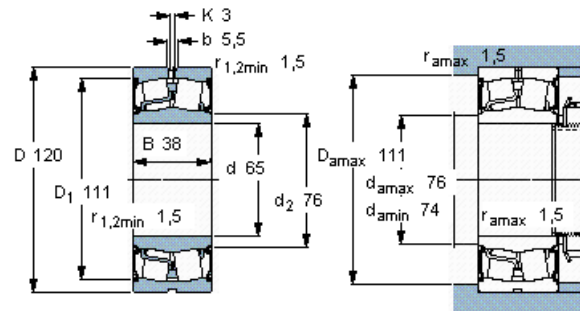

Calculation factors

e 0,24
 Y_1 2,8
 Y_2 4,2
 Y_0 2,8