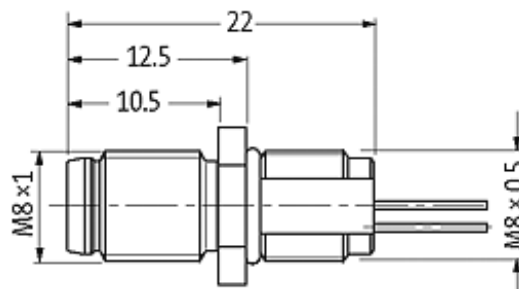
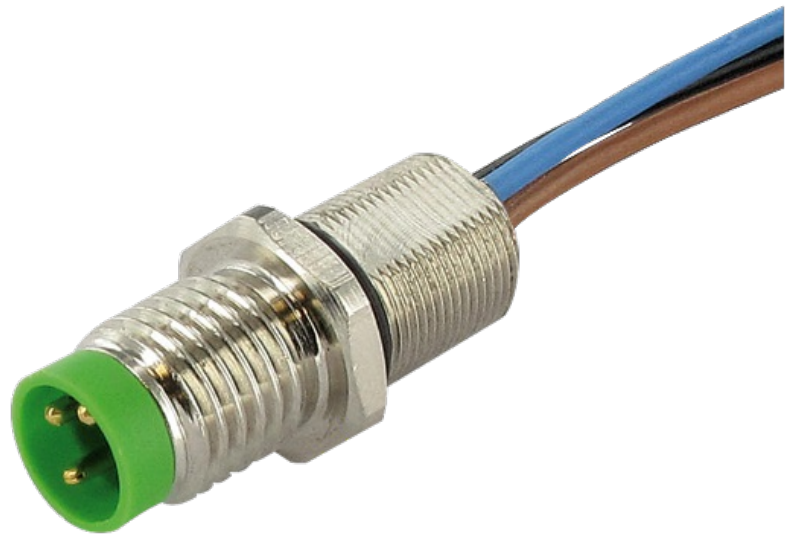
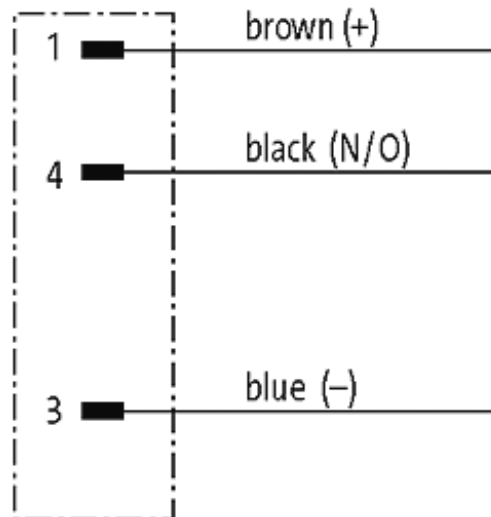



M8 MALE FLANGE PLUG FRONT MOUNT

TPE wires 3x0.25 0.5m

Flange M8 male
with multi-strand wire
3-pole[Link to Product](#)**Illustration**

stay connected

Male

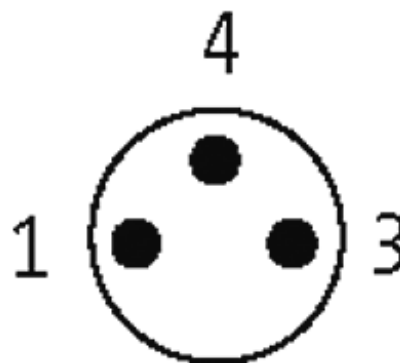

Product may differ from Image

Form

08552

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread M8 × 1 mm (recommended torque 0.4 Nm) self-securing
Protection	IP67 inserted and tightened (EN 60529)

Cables

Cable number	970
No./diameter of wires	3 × 0.25 mm ²
Wire isolation	PP (br, bk, bl)
Shore hardness outer jacket	70 ± 5D
Outer diameter	approx. 1.25 mm
Bend radius (fixed)	5 × outer diameter

Bend radius (moving)	10 × outer diameter
----------------------	---------------------

Temperature range (fixed)	-40...+80 °C
---------------------------	--------------

Temperature range (mobile)	-25...+80 °C
----------------------------	--------------

General data

Temperature range	-25...+85 °C
-------------------	--------------

Commercial data

country of origin	DE
-------------------	----

customs tariff number	85444290
-----------------------	----------

minimum order quantity	1
------------------------	---