


KEMET, Z-SMS, Ferrite Beads, Noise Suppression, 580 mOhms

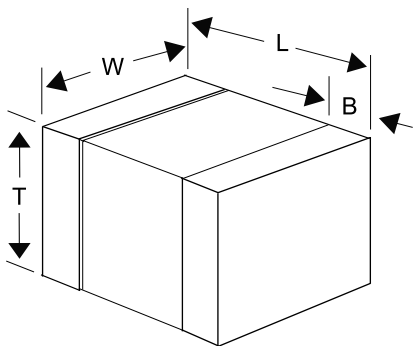

| Dimensions | |
|------------|-----------------|
| Chip Size | 0402 |
| L | 1mm +/-0.05mm |
| W | 0.5mm +/-0.05mm |
| T | 0.5mm +/-0.05mm |
| B | 0.25mm +/-0.1mm |

| Packaging Specifications | |
|--------------------------|-------|
| Packaging: | T&R |
| Packaging Quantity: | 10000 |

| General Information | |
|---------------------|----------------------------------------------------------------------------------------|
| Series: | Z-SMS |
| Style: | SMD Chip |
| Description: | Chip Bead Signal Line |
| Features: | Suppresses The XL Component; Helps Stop The Reduction Of The Wave-Form Integrity |
| RoHS: | Yes |

| Specifications | |
|----------------------|--------------------|
| Impedance: | 600 Ohms (100 mHz) |
| Impedance Tolerance: | 25% |
| Ripple Current: | 300 mA (MAX) |
| Temperature Range: | -55/+125°C |
| Resistance: | 0.58 Ohms |