


# PT-H300

## Professional Handheld Labelling Machine

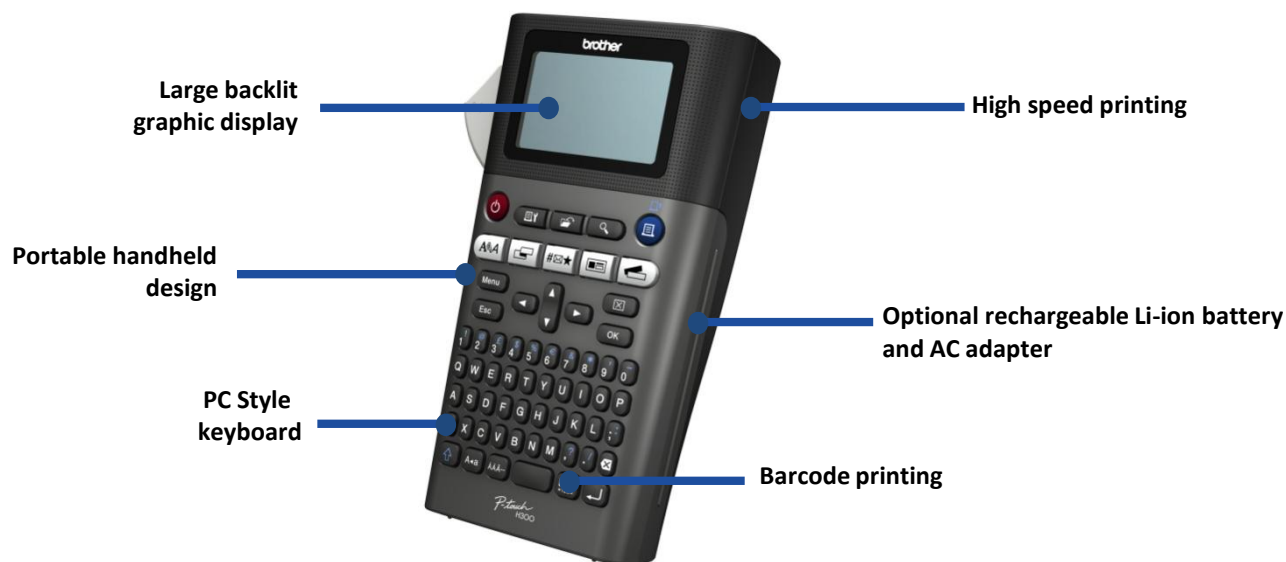

---

### Top Features:

#### Backlit graphic display

- Easy-to-read text and the ability to preview your label before printing.

#### Standard PC style keyboard

- Makes typing efficient.

#### Multiple power options

- Powered by standard alkaline or rechargeable AA batteries, an optional AC adapter and Li-ion rechargeable battery.

#### Convenient labelling

- Handheld design and battery power lets you print labels wherever they are required.

#### Lots of built-in contents

- Customise labels using a choice of 14 fonts, 99 frames and over 600 symbols

# P-touch Office Handheld Datasheet

## PT-H300



### General

|                         |                                                                                                                                                                                                      |
|-------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>Carton contents</b>  | PT-H300 labelling machine<br>18mm black on white 4m tape cassette<br>Wrist strap<br>Quick set-up guide<br>User's guide                                                                               |
| <b>Language support</b> | English, German, French, Spanish, Portuguese, Italian, Dutch, Danish, Norwegian, Swedish, Finnish, Hungarian, Czech, Polish, Romanian, Slovenian, Slovakian, Croatian, Turkish, Brazilian Portuguese |

### Dimensions & Weights

|                                   |                                   |
|-----------------------------------|-----------------------------------|
| <b>Without carton</b>             | 132(w) x 214(d) x 66(h)   670g    |
| <b>With carton</b>                | 345(w) x 249(d) x 102(h)   1.24kg |
| <b>Master carton</b>              | 365(w) x 318(d) x 263(h)   4.59kg |
| <b>Products per master carton</b> | 3                                 |

### Built In Features

|                                |                                                              |
|--------------------------------|--------------------------------------------------------------|
| <b>Keyboard</b>                | 64 Key Rubber QWERTY/QWERTZ/AZERTY                           |
| <b>Dedicated number keypad</b> | Yes                                                          |
| <b>Display type</b>            | Backlit Graphic Monochrome LCD with label preview capability |
| <b>Display resolution</b>      | 15 characters by 3 lines   128 x 56 dots                     |
| <b>Printing speed</b>          | 20mm/second                                                  |
| <b>Print resolution</b>        | 180dpi                                                       |
| <b>Maximum print height</b>    | 15.8mm                                                       |
| <b>Cutter type</b>             | Manual                                                       |
| <b>Label length</b>            | 30mm minimum   300mm maximum                                 |
| <b>Maximum lines per label</b> | 5                                                            |
| <b>Tape margins</b>            | Narrow, Half, Full, Chain Print                              |
| <b>Vertical text printing</b>  | Yes                                                          |
| <b>Mirror printing</b>         | Yes                                                          |
| <b>Copies</b>                  | 1 to 9                                                       |
| <b>Automatic numbering</b>     | 1 to 9   Numeric and Alphanumeric                            |

### Label Creation

|                                 |                                                                                                                                               |
|---------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|
| <b>Fonts</b>                    | 14   Helsinki, Brussels, Belgium, Florida, Los Angeles, San Diego, US, Calgary, Atlanta, Adams, Brunei, Sofia, Germany, Letter Gothic         |
| <b>Font styles</b>              | 12   Normal, Bold, Outline, Shadow, Solid, Italic, Underline, Italic & Bold, Italic & Outline, Italic & Shadow, Italic & Solid, Strikethrough |
| <b>Font sizes</b>               | 6, 9, 12, 18, 24, 36, 42 point                                                                                                                |
| <b>Symbols</b>                  | 617                                                                                                                                           |
| <b>Frames</b>                   | 99                                                                                                                                            |
| <b>Barcodes</b>                 | CODE39, ITF 2/5, EAN13, EAN8, UPC-A, UPC-E, CODABAR, GS1-128 (UCC/EAN128), CODE128                                                            |
| <b>Preset label templates</b>   | 14                                                                                                                                            |
| <b>Label collection designs</b> | 25                                                                                                                                            |
| <b>Cable marking function</b>   | Yes                                                                                                                                           |

### Memory

|                                  |     |
|----------------------------------|-----|
| <b>Max. characters per label</b> | 200 |
| <b>Label memory locations</b>    | 50  |

### Supplies

|                    |                        |
|--------------------|------------------------|
| <b>Tape type</b>   | TZe                    |
| <b>Tape widths</b> | 3.5, 6, 9, 12 and 18mm |

### Optional Accessories

|                   |                                                                                     |
|-------------------|-------------------------------------------------------------------------------------|
| <b>Batteries</b>  | BA-E001 Li-ion rechargeable battery<br>AA alkaline/rechargeable batteries (LR6/HR6) |
| <b>AC adaptor</b> | AD-E001                                                                             |

### Derivative Models (for Germany)

|                      |                                                                     |
|----------------------|---------------------------------------------------------------------|
| <b>PT-H300LI</b>     | Includes BA-E001 Li-ion rechargeable battery and AD-E001 AC adaptor |
| <b>With carton</b>   | 345(w) x 249(d) x 102(h)   1.48kg                                   |
| <b>Master carton</b> | 365(w) x 318(d) x 263(h)   4.88kg                                   |