


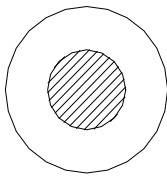

Product Name:	UL1429 28AWG
Product Discription:	UL1429 28AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		150V			Conductor		Stranded Tinned Copper					
Rated Temperature:		80℃			Size(AWG)		28					
Reference Standard:		UL758,UL1581			Construction(±0.008mm)		7/0.127					
Cross Section					Stranded Dia.(mm)Ref.		0.38					
					Insulation Material		XLPVC					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.26					
					Insulation Dia.(±0.06mm)		0.90					
Marking					Remark:							
E148000  AWM STYLE 1429 28AWG 80℃ 150V VW-1 --- C  AWM I A 80℃ 150V FT1 -F- -LF- PC10 LTK					8775254 Red		8775263 Blue		8775276 Grey		8775285 Violet	
					8775257 Black		8775266 White		8775279 Yellow			
					8775250 Brown		8775260 Green		8775272 Orange			
Applications					Characteristics					Customer Approve		
For Internal Wiring of Appliances or Electronic Equipment					Test Item			Standard Value				
					Test Material			XLPVC(ROHS)				
					Max.DC Resistance(20℃ Ω/km)			239(MAX)				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			VW-1				
Revisions												
Version	Description	Drawn by	Approved by	Date								
0	New document issue	Lisa	Jason	18/05/2015								
								Signature:				
								Date:				