



ENGLISH


## Datasheet

# New 5.08mm Plug with Flanges 15A 3 way

RS Stock 874-4745



### Dimensions: (mm)

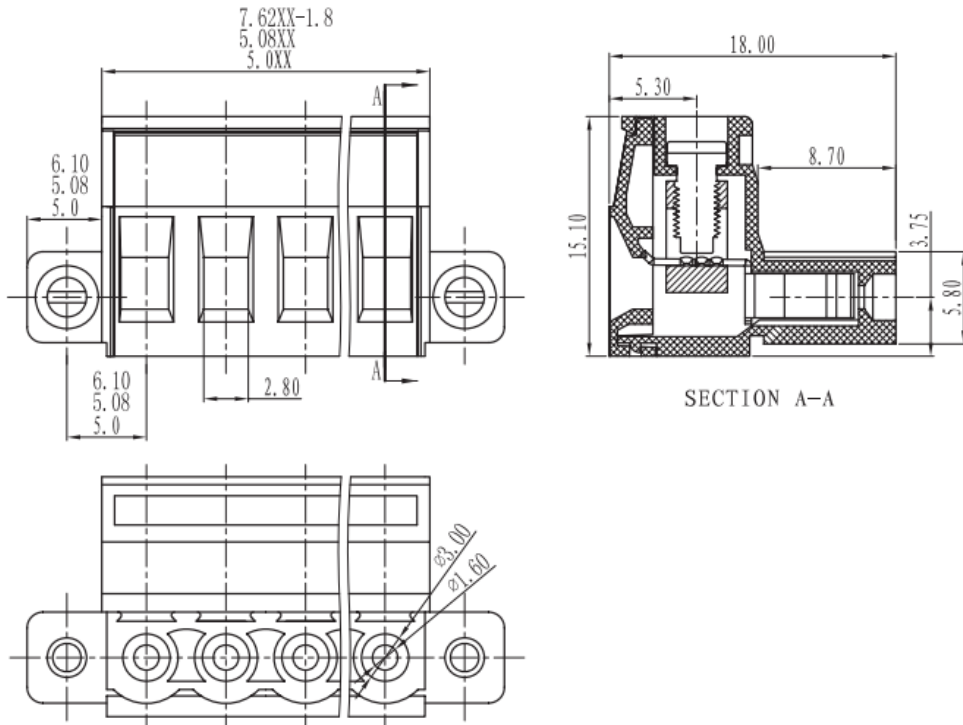



ENGLISH

## Specifications

### Electrical

Standard:	UL	IEC
Rated voltage:	300V	320V
Rated current:	15A	20A
Contact resistance:	20m $\Omega$	
Wire range:	28-14AWG	2.5mm <sup>2</sup>
Withstanding voltage:	AC2000V/1Min	
Insulation resistance:	500M $\Omega$ /DC500V	

### Mechanical

Temp.Range:	-40° C~+105° C
Torque:	0.5Nm(4.51b`in)
Strip length:	7-8mm

### Dimensions

Pitch:	5.00mm,5.08mm,7.62mm
Poles:	2P-24P

### Material

Housing:	PA66,UL94V-0
Screws:	M3.0,steel Zinc plated
Wire guard:	Brass,Ni plated
Clamp:	Phosphor bronze,Ni plated