



10PC. WRENCH SET (METRIC)

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09904	375	180	45	4	10.5

DESCRIPTION:
 2 - Ratcheting Combination Wrenches 13, 14mm
 8 - Double Open End Wrenches
 6 x 7mm, 8 x 10mm, 10 x 12mm, 11 x 13mm,
 12 x 14mm, 22 x 24mm, 24 x 27mm, 30 x 32mm




10PC. DOUBLE BOX END WRENCH SET (METRIC)

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09905	375	180	45	4	10.0


DESCRIPTION:
 6 x 7mm, 8 x 10mm, 10 x 12mm, 11 x 13mm, 12 x 14mm,
 14 x 17mm, 17 x 19mm, 19 x 21mm, 21 x 23mm, 24 x 27mm



30PC. COMBINATION WRENCH AND HEX KEY SET (METRIC)

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09906	375	180	45	4	10.3

DESCRIPTION:
 12 - Combination Wrenches 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
 9 - Extra Long Ball Point Hex Key Set 1.5, 2.0, 2.5, 3, 4, 5, 6, 8, 10mm
 9 - Long Torx Wrenches T10, T15, T20, T25, T27, T30, T40, T45, T50

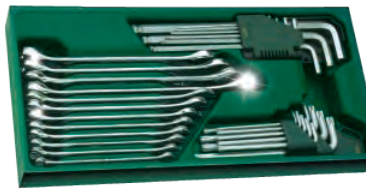


8PC. COMBINATION WRENCH SET (METRIC)

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09907	375	180	45	4	8.8

DESCRIPTION:
 5.5, 6, 7, 20, 21, 22, 23, 24mm




19PC. RATCHETING COMBINATION WRENCH SET (METRIC)

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09908	375	180	45	4	9.2

DESCRIPTION:
 15 - Ratcheting Combination Wrenches
 5.5, 6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
 1 - 1/4" Dr x 10mm Quick Release Adapter
 1 - 3/8" Dr x 13mm Quick Release Adapter
 1 - 1/2" Dr x 19mm Quick Release Adapter
 1 - 1/4" Dr x 10mm Bit Adapter




5PC. ADJUSTABLE WRENCH AND PLIERS SET

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09909	375	180	45	4	8.5


DESCRIPTION:
 2 - Adjustable Wrenches 8", 10"
 1 - Long Nose Pliers 6"
 1 - Curved Jaw Locking Pliers 7"
 1 - Long Nose Locking Pliers 6"



8PC. FILE SET


PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09910	375	180	45	4	6.3

DESCRIPTION:
 1 - Flat File 8"
 1 - Half-Round File 8"
 1 - Square File 8"
 1 - Round File 8"
 1 - Three Square File 8"
 3 - 3 x 140mm Assorted Electroplated Diamond


 Nature of this product is subject to wear and tear upon usage.
 Not covered under Lifetime Warranty.




4PC. SNAP RING PLIERS SET

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09911	375	180	45	4	5.3


DESCRIPTION:
 1 - External Open Straight 7"
 1 - External Open Curved 7"
 1 - Internal Close Straight 7"
 1 - Internal Close Curved 7"

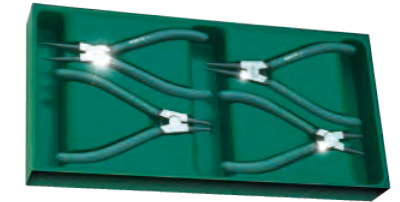

4PC. PLIERS SET

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09912	375	180	45	4	6.6

DESCRIPTION:
 1 - Long Nose 6"
 1 - Diagonal 6"
 1 - Linesman 8"
 1 - Plastic Cutting 6"

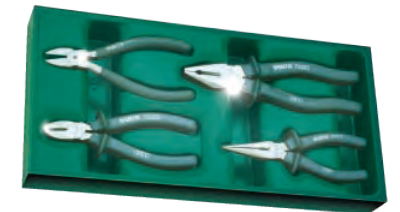

13PC. SCREWDRIVER SET

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09913	375	180	45	4	5.1

DESCRIPTION:
 4 - Precision Slotted 1.0x40mm, 2.0x40mm, 2.4x40mm, 3.0x40mm
 2 - Precision Phillips #3x40mm, #0x40mm
 3 - Slotted 3.0x75mm, 5.0x75mm, 6.0x100mm
 4 - Phillips #0x75mm, #1x75mm, #2x100mm, #3x150mm

