

NEW



WLS28-2 Light Strip, 12-30 VDC

WLS28-2 LED Strip Lights have sturdy aluminum housings, shatterproof windows, and impressive environmental ratings, making them an ideal general-purpose LED light for machine, enclosure, or other industrial lighting applications.

- ▶ Low-Profile, Space-Saving Design
- ▶ Rugged, Water-Resistant IP69K Option
- ▶ Lensed Models or Choice of Clear or Diffuse Window
- ▶ Daisy Chain Power to Multiple Lights
- ▶ Enhanced Light Quality: Brighter, Closer Spaced LEDs
- ▶ Capability to Dim Lights Using the Wiring Pinout (Hi/Low/Off)
- ▶ Automatic Temperature Protection Built into the Unit

Stock No.	Mfr.'s Type	Style	Connection Type	Max Current (A)	Lighted Length (mm)	EACH
70385627	WLS28-2XW145XPB*	Stand-Alone	2 m Cable	0.4	145	114.00
70385628	WLS28-2XW285XPB*	Stand-Alone	2 m Cable	0.8	285	144.00
70385629	WLS28-2XW430XPB*	Stand-Alone	2 m Cable	1.2	430	194.00
70385680	WLS28-2XW570XPB*	Stand-Alone	2 m Cable	1.6	570	224.00
70385780	WLS28-2XW710XPB*	Stand-Alone	2 m Cable	2.0	710	274.00
70385781	WLS28-2XW850XPB*	Stand-Alone	2 m Cable	2.4	850	304.00
70385782	WLS28-2XW990XPB*	Stand-Alone	2 m Cable	2.8	990	354.00
70385783	WLS28-2XW1130XPB*	Stand-Alone	2 m Cable	3.2	1130	384.00
70385615	WLS28-2CW145XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	0.4	145	124.00
70385616	WLS28-2CW285XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	0.8	285	154.00
70385617	WLS28-2CW430XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	1.2	430	204.00
70385618	WLS28-2CW570XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	1.6	570	234.00
70385619	WLS28-2CW710XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	2.0	710	284.00
70385640	WLS28-2CW850XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	2.4	850	314.00
70385641	WLS28-2CW990XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	2.8	990	364.00
70385643	WLS28-2CW1130XPBQ*	Stand-Alone and Cascadable	4-Pin Euro QD	3.2	1130	394.00
70385644	WLS28-2CW145XQ	Cascadable	4-Pin Euro QD	0.4	145	109.00
70385645	WLS28-2CW285XQ	Cascadable	4-Pin Euro QD	0.8	285	139.00
70385646	WLS28-2CW430XQ	Cascadable	4-Pin Euro QD	1.2	430	189.00
70385647	WLS28-2CW570XQ	Cascadable	4-Pin Euro QD	1.6	570	219.00
70385648	WLS28-2CW710XQ	Cascadable	4-Pin Euro QD	2.0	710	269.00
70385649	WLS28-2CW850XQ	Cascadable	4-Pin Euro QD	2.4	850	299.00
70385670	WLS28-2CW990XQ	Cascadable	4-Pin Euro QD	2.8	990	349.00
70385672	WLS28-2CW1130XQ	Cascadable	4-Pin Euro QD	3.2	1130	379.00
70385557	WLS28-2CW145SQ	Sealed/Cascadable	4-Pin Euro QD	0.4	145	149.00
70385558	WLS28-2CW285SQ	Sealed/Cascadable	4-Pin Euro QD	0.8	285	179.00
70385559	WLS28-2CW430SQ	Sealed/Cascadable	4-Pin Euro QD	1.2	430	229.00
70385800	WLS28-2CW570SQ	Sealed/Cascadable	4-Pin Euro QD	1.6	570	259.00
70385801	WLS28-2CW710SQ	Sealed/Cascadable	4-Pin Euro QD	2.0	710	309.00
70385802	WLS28-2CW850SQ	Sealed/Cascadable	4-Pin Euro QD	2.4	850	339.00
70385803	WLS28-2CW990SQ	Sealed/Cascadable	4-Pin Euro QD	2.8	990	389.00
70385805	WLS28-2CW1130SQ	Sealed/Cascadable	4-Pin Euro QD	3.2	1130	419.00
70385677	WLS28-2CW145L25XQ	Lensed/Cascadable	4-Pin Euro QD	0.4	145	111.00
70385678	WLS28-2CW285L25XQ	Lensed/Cascadable	4-Pin Euro QD	0.8	285	143.00
70385679	WLS28-2CW430L25XQ	Lensed/Cascadable	4-Pin Euro QD	1.2	430	195.00
70385790	WLS28-2CW570L25XQ	Lensed/Cascadable	4-Pin Euro QD	1.6	570	227.00
70385673	WLS28-2CW710L25XQ	Lensed/Cascadable	4-Pin Euro QD	2.0	710	279.00
70385674	WLS28-2CW850L25XQ	Lensed/Cascadable	4-Pin Euro QD	2.4	850	311.00
70385675	WLS28-2CW990L25XQ	Lensed/Cascadable	4-Pin Euro QD	2.8	990	363.00
70385676	WLS28-2CW1130L25XQ	Lensed/Cascadable	4-Pin Euro QD	3.2	1130	395.00

*Hi/Low/Off switch.




WLA LED Area Lights

- ▶ High Power Solid State LED Array with Cool White Light (Other Colors Available)
- ▶ Illuminates a Large Area with an Even Pattern of Light and No Shadows
- ▶ Designed for Area and Machine Lighting
- ▶ Lensed Models Provide a Concentrated, More Intense Beam Pattern
- ▶ Available in Four Sizes
- ▶ Rugged Encapsulated Housing Rated to IP69K



Stock No.	Mfr.'s Type	Style	Connections	L (mm)	Input Voltage (VDC)	EACH
70168024	WLAW105X180	Area Light	2 m	105.1	12-30	198.95
70168025	WLAW105X180Q	Area Light	4-Pin Euro QD	105.1	12-30	198.95
70168026	WLAW190X180	Area Light	2 m	180.1	12-30	338.95
70168027	WLAW190X180Q	Area Light	4-Pin Euro QD	180.1	12-30	338.95
70168028	WLAW275X180	Area Light	2 m	275.0	12-30	488.95
70168029	WLAW275X180Q	Area Light	4-Pin Euro QD	275.0	12-30	488.95
70168030	WLAW360X180	Area Light	2 m	356.6	12-30	628.95
70168031	WLAW360X180Q	Area Light	4-Pin Euro QD	356.6	12-30	628.95
70280084	WLAW105X180L11Q	Lensed Area Light	4-Pin Euro QD	105.1	12-30	244.95
70280086	WLAW190X180L11Q	Lensed Area Light	4-Pin Euro QD	180.1	12-30	428.95
70280087	WLAW275X180L11Q	Lensed Area Light	4-Pin Euro QD	275.0	12-30	624.95
70280088	WLAW360X180L11Q	Lensed Area Light	4-Pin Euro QD	356.6	12-30	798.95
70280237	WLAW105X180EQ	Encapsulated Area Light	4-Pin Euro QD	105.1	12-30	208.95
70280238	WLAW190X180EQ	Encapsulated Area Light	4-Pin Euro QD	180.1	12-30	358.95
70280239	WLAW275X180EQ	Encapsulated Area Light	4-Pin Euro QD	275.0	12-30	518.95
70280280	WLAW360X180EQ	Encapsulated Area Light	4-Pin Euro QD	356.6	12-30	668.95

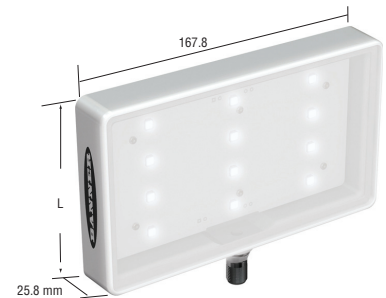

WLA LED Area Light Mounts



Stock No.	Mfr.'s Type	Style	EACH
70280019	SMBBSSM	Flange Standoff Mount	35.99
70280080	SMBWLSMAG	Magnetic Mount	7.99
70280082	SMBWLSMAGR	Rubber Cover for Magnetic Mount	4.99
70280083	SMBBSRA	Pivot Flange Mount	29.99

