


Datasheet

Non-Fused Terminal Block, 3 Way, Screw Down, Nylon, 450 V

RS Stock 465-637



Dimensions: (mm)

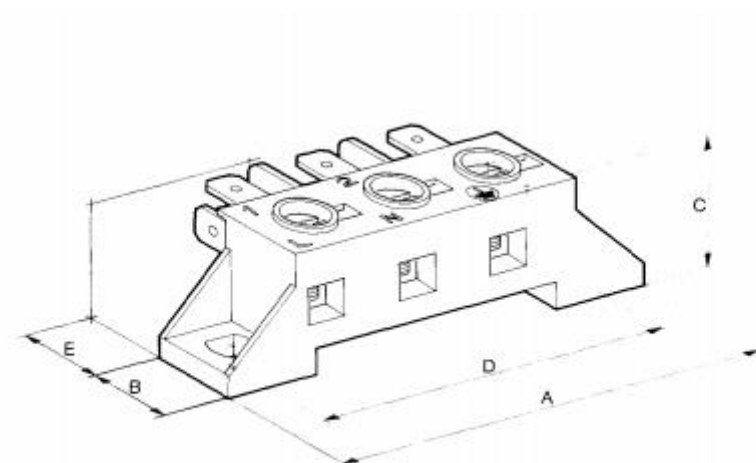

TECHNICAL DATA	FV 110	FV 173	FV 122
poles	3	4	6
marking	L N ⊕	L ₁ L ₂ N ⊕	1 2 3 4 5 ⊕
rating [6 mm ²]	40A-450V		
dimensions [mm]	A 81,5	99	135 A
	B 15	15	15 B
	C 24,5	24,5	24,5 C
	D 66,5	84,2	120,5 D
	E 16,5	16,5	16,5 E
	F —	—	37 F

housing

brown glass filled polyamide 6.6
self-extinguishing to

CEI 23-20, UL 94 V₀ and IEC 695-2-1 to 850 °C

temperature

150 °C
peak 200 °C per brevi periodi

metal parts

zinc passivated steel:
triple **tabs** per pole
underhead knurled **screws** M 5x10
3,5 mm thread engagement
nuts
6 mm² section **shorting links**

creepage and clearance

not less than 9,5 mm between
live parts and the bas in
accordance with CENELEC HD 251 S2
CEI 61-50 §29-3

options

available without one or more
metal parts, different polarity
symbols, different position and
number of the shorting links