



# Datasheet

## RS Slotted Trunking

RS Stock number 758-9317

ENGLISH

### SPECIFICATION


- Material: High impact, warp-proof, self-extinguishing PVC
- UL approved 94V-0
- Maximum service temperature: 85°C
- Test to UL file E97527 up to 50 °C
- Standards: UL, CSA approved
- Color: Grey
- Trunking length 2 metres
- Supplied complete with cover
- Pack quantity is 8 lengths

RS Stock Number	W (mm)	H (mm)	B (mm)
758-9204	25	30	6
758-9213	25	40	9
758-9216	25	60	13
758-9210	25	80	18
758-9229	40	40	11
758-9222	40	60	13
758-9226	40	80	10
758-9235	60	40	9
758-9238	60	60	13
758-9232	60	80	10
758-9241	60	100	15
758-9244	80	60	13
758-9248	80	80	13
758-9257	80	100	15
758-9250	100	40	11
758-9254	100	80	14
758-9263	100	100	16
758-9266	120	60	17

RS Stock Number	W (mm)	H (mm)	B (mm)
758-9260	15	25	6
758-9279	25	30	6
758-9272	25	40	10
758-9276	25	60	13
758-9285	25	80	19
758-9288	40	40	10
758-9282	40	60	13
758-9291	40	80	11
758-9294	60	40	10
758-9298	60	60	13
758-9308	60	80	11
758-9301	60	100	15
758-9305	80	60	13
758-9314	80	80	13
758-9317	80	100	15
758-9311	100	40	11
758-9320	100	80	13

Dimensions – mm

## NARROW 4mm SLOT

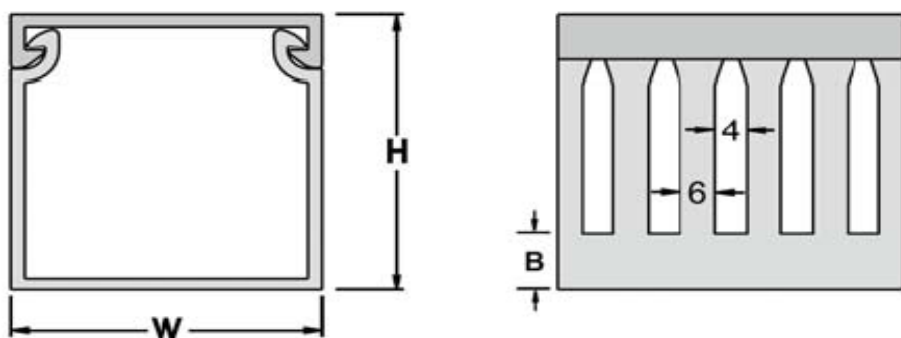

## STANDARD 8mm SLOT

