
8024

Lamps without halogen, low voltage

Areas of application

- As film projector lamps



 

Product datasheet

Technical data

Electrical data

Nominal voltage	12.0 V
Nominal wattage	40.00 W
Lamp wattage	40 W

Dimensions & weight

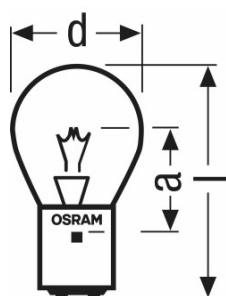

BA20d
IEC 7004-12
DIN 49730

IEC 7005-14
DIN 49735

Diameter	35.0 mm
Light center length (LCL)	30.0 mm
Length	67.0 mm

Lifespan

Lifespan	500 h
----------	-------

Additional product data

Base (standard designation)	BA20d
-----------------------------	-------

Capabilities

Burning position	≤135
------------------	------


Country specific categorizations

Order reference	8024 40W 12V BA
-----------------	-----------------

Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4050300013817	OSRF8024	-	4739346	-

Product datasheet

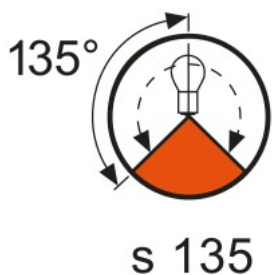

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300013817	8024	Folding carton box 1	36 mm x 36 mm x 69 mm	0.09 dm ³	24.67 g
4050300206660	8024	Shipping carton box 100	191 mm x 172 mm x 409 mm	13.44 dm ³	2400.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.