

Datasheet

40m Heavy Duty Metal Open Reel

RS Stock number 889-2501




Description:

This larger plastic constructed extension reel has been designed and engineered for efficiency. The plastic drum provides reliable protection when in use, transported or stored. Using highly visible green cable, this range of extension reels provides four shuttered, LED indicator, power switch and has a built-in safety thermal cut-out for protection against overloading when fully reeled.

Product Information

Part No:	889-2501
Type:	Heavy Duty Metal Open Cable Reel
Cable Type:	PVC
Cable Length (m):	40
Amp:	13
Product Dimensions:	H:10.8 x W:9.6 x D:8.2
(Inch/cm)	H:27.5 x W:24.5 x D:21

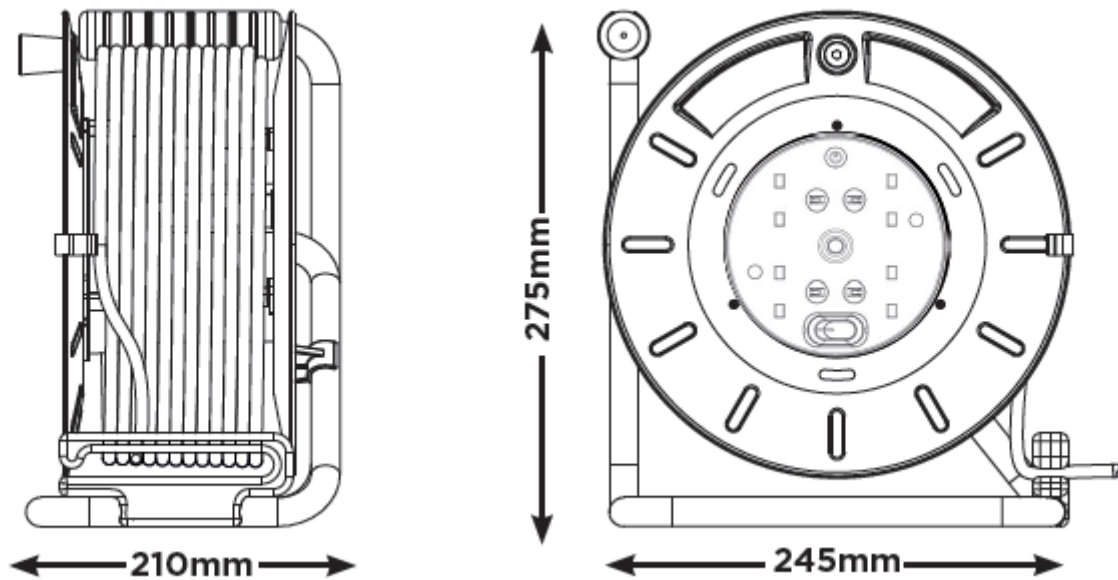

Specifications:

Standards:	BS EN 61242. ASTA Approved
Maximum Load:	720W/240V - Fully Wound 3120W/240V - Fully Unwound
Switch:	Double Pole
Cable length	40m
Cable Size:	Cable Size - 1.25mm ² (HO5VV-F)

Features

- » Robust case reel, with four shutter sockets
- » Safety thermal cut-out
- » Power on/off switch
- » Power LED indicator