

Cable sleeve - CES-STPG-GY-2X7 - 1410110

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Small, slotted cable sleeves suitable for two cables with a diameter of 6 ... 7 mm, material: SEBS



Key commercial data

Packing unit	10 pc
GTIN	 4 046356 776257
Weight per Piece (excluding packing)	7.15 g
Custom tariff number	85472000
Country of origin	Poland

Technical data

Dimensions

External cable diameter	2x 6 mm ... 7 mm
-------------------------	------------------

Ambient conditions

Degree of protection	IP54
	IP55 (when using a CES-B...-SFFS-PLBK sealing frame with screw locking)
Ambient temperature (operation)	-40 °C ... 80 °C (static)

General

Material	SEBS
Inflammability class according to UL 94	V0
Color	gray

Classifications

eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002

Cable sleeve - CES-STPG-GY-2X7 - 1410110

Classifications

eCl@ss

eCl@ss 5.0	27081002
eCl@ss 5.1	27081002
eCl@ss 6.0	27081002
eCl@ss 7.0	27081002
eCl@ss 8.0	27081002

ETIM

ETIM 3.0	EC000879
ETIM 4.0	EC002498
ETIM 5.0	EC000451

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / cULus Recognized

Ex Approvals

Approvals submitted


Approval details

UL Recognized

cUL Recognized


Cable sleeve - CES-STPG-GY-2X7 - 1410110

Approvals

cULus Recognized  US

Drawings

Dimensioned drawing

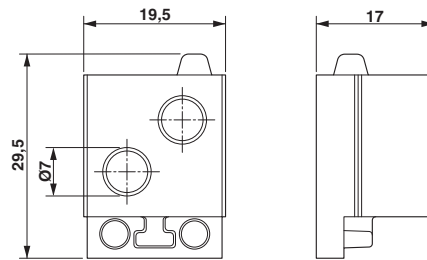

Dimensional drawing