

# PHILIPS


## 6874P 300W GY9.5 230V 1CT



### General

PRODUCT DATA	
Order code	187796 25
Full product code	871150018779625
Full product name	6874P 300W GY9.5 230V 1CT
Order product name	6874P 300W GY9.5 230V 1CT/10
Packing type	1 Carton
Pieces per pack	1
Packing configuration	10
Packs per outerbox	10
Bar code on pack - EAN1	8711500187796
Bar code on intermediate packing - EAN2	-
Bar code on outerbox - EAN3	8711500187819
Logistic code(s) - 12NC	9239 497 43228
ILCOS code	-
Net weight per piece	0.018 (KG)
Successor order code	-
Philips Code	6874P
Rated Lamp Wattage[W ]	300W
Cap-Base	GY9.5
Voltage[V ]	230V
Packing Type	1CT [1 Carton]
Packing Configuration	10
ANSI Code	-
LIF Code	M/38
System Description	-
Bulb Finish	Clear
Filament Shape	M
Burning Position	any
Main Application	Entertainment
Life to 50% failures[hr ]	2000
Product Nett Weight[gr ]	18.5
Rapid Acting HBC Fuse[V ]	2
Lamp Luminous Flux[Lm ]	5200
Filament Dimensions (WxH) [mm]	8x14

## Dimensions

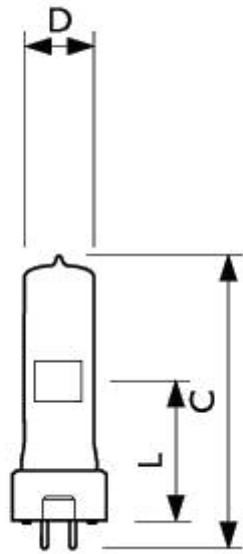

### PRODUCT DIMENSIONS

Characteristic	Value
Overall Length C	79 mm
Diameter D	17 mm
Light Center Length L	46.5 mm