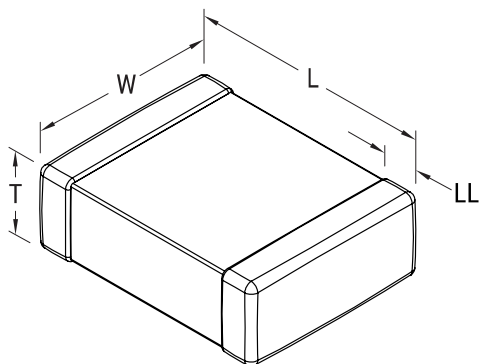


KEMET, L-RMS, RF, 100 nH, 5%

**Dimensions**

Chip Size	0603
L	1.6mm +/-0.15mm
W	0.8mm +/-0.15mm
T	0.8mm +/-0.15mm
LL	0.3mm +/-0.2mm

Packaging Specifications

Packaging:	T&R
Packaging Quantity:	4000

General Information

Series:	L-RMS
Style:	SMD Chip
Description:	Surface Mount Inductor
RoHS:	Yes
Core:	Ceramic
Winding Type:	Multilayer

Specifications

Inductance:	0.1 uH (100 MHz)
Inductance Tolerance:	5%
Temperature Range:	-40/+85C
Current:	300 mAmps (MAX)
DC Resistance:	1 Ohms
Quality Factor:	18 at 100 MHz, 28 at 500 MHz, 16 at 800 MHz
Self-Resonant Frequency:	600 MHz