

## ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E27 SL

0026929



### Range features

- Up to 88% energy saving compared to incandescent lamps
- Instant light
- 100% retrofit - Same dimensions as incandescent equivalent
- Suitable for replacement of up to 25W and 40W incandescent lamps
- Uniform light distribution
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs

CE

### PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026929
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Candle
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E27
Type	ToLEDo Candle
EAN code	5410288269290
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	470
Watt (Nominal) (W)	6.5
Equivalent watt (W)	40
Voltage (V)	220-240

# ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E27 SL

**0026929**

## DATA TABLE

### General data

<b>Dry applications use only</b>	Yes
<b>Ordering number</b>	0026929
<b>Technology</b>	LED
<b>Energy saving lamp</b>	Yes
<b>Average life (Nominal) (h)</b>	25000
<b>Average life (Rated) (h)</b>	25000
<b>Energy class</b>	A+
<b>Lamp finish</b>	Clear
<b>Lamp shape</b>	Candle
<b>Dimmable</b>	Yes
<b>Cap/Base</b>	E27
<b>Type</b>	ToLEDo Candle
<b>EAN code</b>	5410288269290
<b>Long description</b>	Up to 88% energy saving compared to incandescent lamps. Instant light. 100% retrofit - Same dimensions as incandescent equivalent. Suitable for replacement of up to 25W and 40W incandescent lamps. Uniform light distribution. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
<b>Product name</b>	ToLEDo Candle Dim Clear 470LM E27 SL
<b>Lamp mercury content (mg)</b>	0
<b>Starting time (max) (s)</b>	0.05
<b>Warm-up time to 60% of full light (max) (s)</b>	< 1s => 60%
<b>Control gear required</b>	No
<b>Intended purpose</b>	No
<b>No. of switching cycles before premature failure (min)</b>	50000
<b>Special purpose lamp</b>	No
<b>Sales pack quantity</b>	6
<b>Optimal operating condition (°C)</b>	25

### Optical data

<b>Light colour</b>	Homelight
<b>CRI (Ra)</b>	80
<b>Colour temperature (K)</b>	2700
<b>Luminous flux (Rated) (lm)</b>	470
<b>Lumen maintenance at end of nominal life (%)</b>	70
<b>Luminous flux (Nominal) (lm)</b>	470

## ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E27 SL

**0026929**

### Electrical data

<b>kWh per 1000 hours burning time</b>	7
<b>Watt (Rated) (W)</b>	6.5
<b>Watt (Nominal) (W)</b>	6.5
<b>Equivalent watt (W)</b>	40
<b>Voltage (V)</b>	220-240
<b>Lamp power factor</b>	0.55

### Physical data

<b>Weight (kg)</b>	0.09
<b>Lamp Length (mm) - C/L</b>	113
<b>Max. Lamp Diameter (mm) - D</b>	38
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	12.60 x 4.80 x 4.80
<b>Inner package dimensions (L x W x H) (cm)</b>	15.50 x 10.50 x 14.10
<b>Inner package net weight (kg)</b>	0.51
<b>Outer package dimensions (L x W x H) (cm)</b>	55.00 x 32.60 x 16.10


## ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E27 SL

0026929

### TECHNICAL DRAWINGS

---

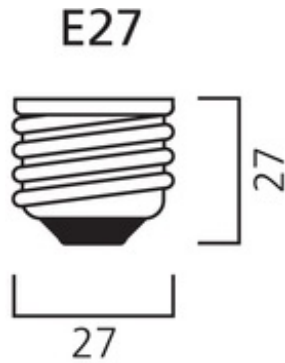

### ENERGY LABEL

---

