


Spherical roller bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
55	100	31	125	127	13,7	-	1700	1,00	BS2-2211-2CS/VT143 *

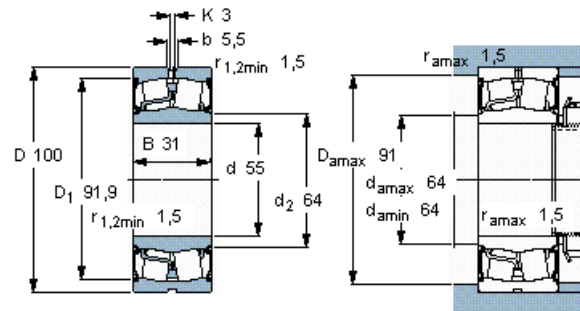

Calculation factors

e 0,24
 Y_1 2,8
 Y_2 4,2
 Y_0 2,8