

Magnastat controlled line voltage soldering irons

W 61

- 60 W, 230 V



CT 5 Soldering tip series
page 177

Order-no.	Model	Description
T005 61 036 99	W 61	Line voltage soldering iron 60 W, 230 V, Magnastat controlled



W101

- 100 W, 230 V
- Complete with soldering tip CT6E7 and safety rest



CT 6 Soldering tip series
page 178

Order-no.	Model	Description
T005 61 046 99	W 101	Low voltage soldering iron 100 W, 230 V, Magnastat controlled

W 101SP

- 100 W, 230 V
- Complete with welding wedge Teflon coated 50 x 40 x 4 mm, twist lock and safety rest

Welding wedge spare
page 178

Order-no.	Model	Description
T005 61 096 99	W 101SP	Line voltage soldering iron 100 W, 230 V, Magnastat controlled with welding wedge (260°C-295°C)



W 201

- 200 W, 230 V
- Complete with soldering tip CT2F7 and safety rest

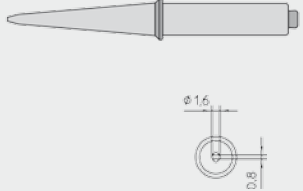
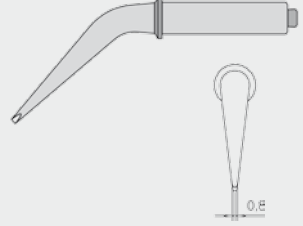
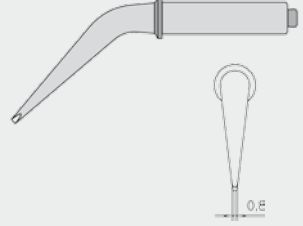


CT 2 Soldering tip series
page 179

Order-no.	Model	Description
T005 61 056 99	W 201	Line voltage soldering iron 200 W, 230 V, Magnastat controlled

CT5 Soldering Tip Series

 
 
Soldering Tips for W 61

Order-no.	Model	Description	Width A	
4CT5A6	CT5 A6	Chisel tip 310°C	1,6 mm	
4CT5A7	CT5 A7	Chisel tip 370°C	1,6 mm	
4CT5A8	CT5 A8	Chisel tip 425°C	1,6 mm	
4CT5B7	CT5 B7	Chisel tip 370°C	2,4 mm	
4CT5B8	CT5 B8	Chisel tip 425°C	2,4 mm	
4CT5C6	CT5 C6	Chisel tip 310°C	3,2 mm	
4CT5C7	CT5 C7	Chisel tip 370°C	3,2 mm	
4CT5C8	CT5 C8	Chisel tip 425°C	3,2 mm	
4CT5D7	CT5 D7	Chisel tip 370°C	4,7 mm	
4CT5D8	CT5 D8	Chisel tip 425°C	4,7 mm	
T005 42 107 99	CT5 AX7	Chisel tip bent 370°C	1,6 mm	
T005 42 108 99	CT5 AX8	Chisel tip bent 425°C	1,6 mm	
T005 42 117 99	CT5 BX7	Chisel tip bent 370°C	2,4 mm	
T005 42 128 99	CT5 CX8	Chisel tip bent 425°C	3,2 mm	
T005 42 138 99	CT5 DX8	Chisel tip bent 425°C	5,0 mm	

Soldering Tips

CT6 Soldering Tip Series

Soldering Tips for W 101

Order-no.	Model	Description	Width A	
4CT6C7	CT6 C7	Chisel tip 370°C	3,2 mm	
4CT6C8	CT6 C8	Chisel tip 425°C	3,2 mm	
4CT6D7	CT6 D7	Chisel tip 370°C	5,0 mm	
4CT6D8	CT6 D8	Chisel tip 425°C	5,0 mm	
4CT6E7	CT6 E7	Chisel tip 370°C	7,0 mm	
4CT6E8	CT6 E8	Chisel tip 425°C	7,0 mm	
T005 42 307 99	CT6 CX7	Chisel tip bent 370°C	3,2 mm	
T005 42 318 99	CT6 DX8	Chisel tip bent 425°C	5,0 mm	



Welding wedge

Order-no.	Description
T005 11 767 99	Welding wedge Teflon beschichtet, 50 x 40 x 4 mm (260°C–295°C) for W 101SP with twist lock
T005 11 767 74	Welding wedge PTFEcoated, 50 x 40 x 4 mm

Adapter

For use with LHT tips (page xx) and soldering iron W 101

Order-no.	Model	Description
T005 61 046 67	CT6-7	Adapter for LHT tips, 370°
T005 61 046 68	CT6-8	Adapter for LHT tips, 425°
T005 61 046 69	CT6-9	Adapter for LHT tips, 480°