
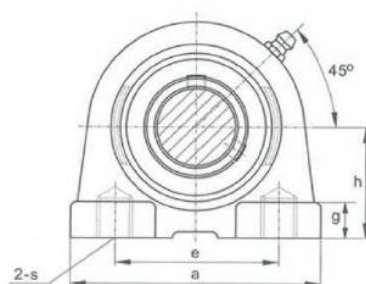


## 2 Bolt Pillow block Tapped base – Metric

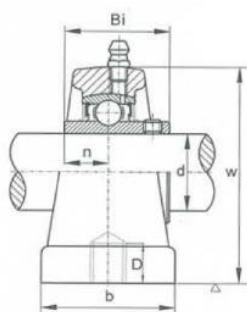

| RS Article no. | Bearing unit No. | Shaft Dia. | Dimension (mm) |     |    |    |     |    |     |    |      |      | Bolt used | Bearing No. | Housing No. | Weight (kg) |
|----------------|------------------|------------|----------------|-----|----|----|-----|----|-----|----|------|------|-----------|-------------|-------------|-------------|
|                |                  | d (mm)     | h              | a   | e  | b  | s   | g  | w   | D  | Bi   | n    | (mm)      |             |             |             |
| 7509015        | UCPA204          | 20         | 30.2           | 76  | 52 | 40 | M10 | 11 | 62  | 13 | 31.0 | 12.7 | M10       | UC 204      | PA 204      | 0.64        |
| 7509018        | UCPA205          | 25         | 36.5           | 84  | 56 | 45 | M10 | 12 | 72  | 13 | 34.0 | 14.3 | M10       | UC 205      | PA 205      | 0.83        |
| 7509012        | UCPA206          | 30         | 42.9           | 94  | 66 | 50 | M14 | 12 | 84  | 18 | 38.1 | 15.9 | M14       | UC 206      | PA 206      | 1.2         |
| 7509021        | UCPA207          | 35         | 47.6           | 110 | 80 | 55 | M14 | 13 | 95  | 20 | 42.9 | 17.5 | M14       | UC 207      | PA 207      | 1.7         |
| 7509024        | UCPA208          | 40         | 49.2           | 116 | 84 | 58 | M14 | 13 | 100 | 20 | 49.2 | 19.0 | M14       | UC 208      | PA 208      | 2.0         |
| 7509028        | UCPA209          | 45         | 54.2           | 120 | 90 | 60 | M14 | 13 | 108 | 25 | 49.2 | 19.0 | M14       | UC 209      | PA 209      | 2.2         |
| 7509037        | UCPA210          | 50         | 57.2           | 130 | 94 | 64 | M16 | 14 | 116 | 25 | 51.6 | 19.0 | M16       | UC 210      | PA 210      | 2.8         |