

## 64633 HLX

---

Low-voltage halogen lamps without reflector



### Product features

---

- Xenon instead of krypton as the filler gas (XENOPHOT HLX versions)
- Luminous flux up to 10 % higher with same power consumption (XENOPHOT HLX versions)

## Technical data

---

### Electrical data


Nominal wattage	150 W
Nominal voltage	15 V

### Light technical data

Nominal luminous flux	5600 lm
Luminous flux	5600 lm

### Dimensions & weight

Diameter	11.5 mm
Filament length	3.00 mm
Light center length (LCL)	30.0 mm
Length	44.0 mm
Filament diameter	4.8 mm

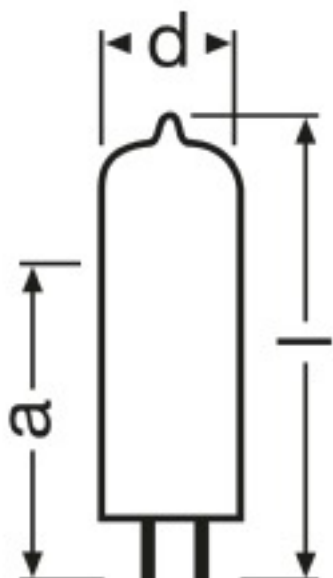

Product line drawing with letters



Base

### Lifespan

Lifespan	50 h
----------	------

### Additional product data

Base (standard designation)	G6.35
-----------------------------	-------

### Capabilities

Burning position	s90
------------------	-----

### Country specific categorizations

ANSI code	BRJ
LIF	A1/234
Order reference	64633 HLX



*Burning position*



*Burning position*

**Logistical Data**

Product code	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Gross weight	Volume
4050300006710	Folding carton box 1	26 mm x 24 mm x 68 mm	6.00 g	0.04 dm <sup>3</sup>
4050300890616	Shipping carton box 40	121 mm x 107 mm x 144 mm	249.00 g	1.86 dm <sup>3</sup>

## Disclaimer

---

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.