


Part no. : 7605

Receptacle



switched, with mechanical DUO-interlock; can be padlocked

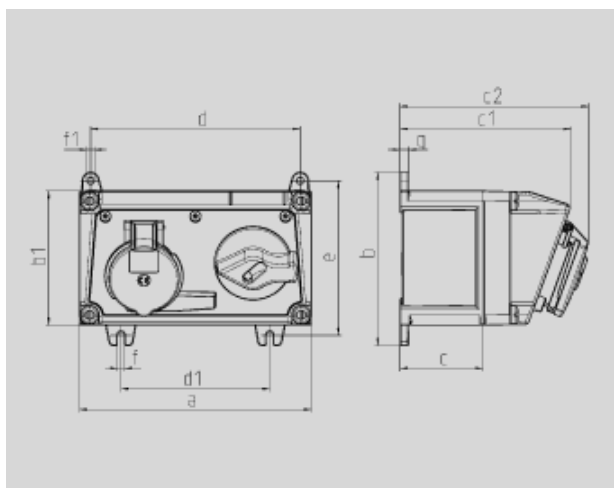

Drawing 1 MB 550 Dim. in mm	Amp. Poles	16			32		
		3	4	5	3	4	5
a		225	225	225	225	225	225
b		168	168	168	168	168	168
b1		130	130	130	130	130	130
c		80	80	80	80	80	80
c1		166	166	166	166	166	166
c2		182	183	183	193	193	193
d		204	204	204	204	204	204
d1		145	145	145	145	145	145
e		150	150	150	150	150	150
f		7	7	7	7	7	7
f1		Ø7	Ø7	Ø7	Ø7	Ø7	Ø7
g		8	8	8	8	8	8

Article-group : **1100**

voltages : 400V

rated current : 16A

pole : 4 pole

IP protection types : 44

position of ground contact : 6h

weight : 1308

PART NUMBERS

		V	110V	230V	400V	500V	>50-500V
Hz			50,60	50,60	50,60	50,60	100-300 300-500
colour							
amp.							
16 A	3		7602	7603			
	4			7604	7605	7606	
	5				7607		
32 A	3		7611	7612			
	4			7613	7614	7615	
	5				7616		