

Hi-Force®

HYDRAULIC TOOLS




Global Brand
Local Service



Jacks - Pumps - Cutters - Presses - Cylinders - Puller kits - Spreaders - Pipe benders
Torque tools - Bolt tensioners - Nut splitters - Hole punchers
Moving skates - Crimping tools - Hydrotest pumps - Toughlift jacking systems

REPLACEMENT PARTS

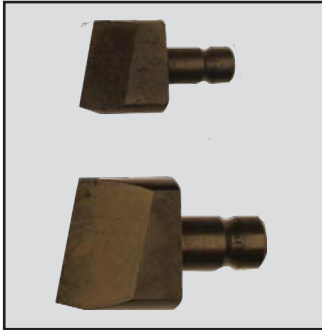

Hi-Force supplies comprehensive service kits, containing all of the “wear and tear” parts necessary to guarantee the correct performance and integrity of your Hi-Force equipment. Always specify and order genuine Hi-Force service kits and spare parts. Please provide product serial number when ordering to ensure correct parts are supplied. Complete spare parts information including exploded view part sheets can be found on our website : www.hi-force.com



REPLACEMENT BLADES	
For model number	Blade part no.
CT20 moving	CT20-04
CT20 static	CT20-05
CT40 moving	CT40-11
CT40 static	CT40-05
DNS404	DNS404-B
DNS506	DNS506-B
HCC26 Gr 80 static	HCC26-4S
HCC26 Gr 80 moving	HCC26-4M
HCC26 Gr 100 static	HCC26-4S100
HCC26 Gr 100 moving	HCC26-4M100
HCC34 Gr 80 static	HCC34-5S
HCC34 Gr 80 moving	HCC34-5M
HCC34 Gr 100 static	HCC34-5S100
HCC34 Gr 100 moving	HCC34-5M100
HCC46 Gr 80 static	HCC46-11S
HCC46 Gr 80 moving	HCC46-11M
HCC46 Gr 100 static	HCC46-11S100
HCC46 Gr 100 moving	HCC46-11M100
HCH40 moving	CT40-11
HCH40 static	CT40-05
HCH120 moving	HCH120-01
HCH120 static	HCH120-02
HMNS104	NS104-B
HMNS110	NS110-B
HMNS200	NS200-B
HWRC1115	HWRC1115-B
HWRC1125	HWRC1125-B
HWRC1136	HWRC1136-B
HWRC1145	HWRC1145-B
HSWC19	HSWC19-4
HSWC28	HSWC28-4
HSWC44	HSWC44-4
NS104	NS104-B
NS110	NS110-B
NS200	NS200-B
NS206	NS206-B
NS215	NS215-B

COMPREHENSIVE SERVICE KITS	
For model number	Service kit part no.
AHP112	AHP112TP2-K
AHP114	AHP114TP2-K
AHP10	AHP10TP1-K
AHP26	AHP26TP1-K
AHP36	AHP36TP1-K
AHP58	AHP58TP1-K
AHP107	AHP107TP1-K
AHP187	AHP187TP1-K
AHP275	AHP275TP1-K
AHP425	AHP425TP1-K
AHP2-036	AHP2-036TP1-K
AHP2-060	AHP2-060TP1-K
AHP2-097	AHP2-097TP1-K
AHP2-144	AHP2-144TP1-K
AHP2-237	AHP2-237TP1-K
AHP275BTU	AHP275TP1-K
ATDP63	ATDP63TP1-K
ATDP125	ATDP125TP1-K
ATDP216	ATDP216TP1-K
BC18X	BC18TP1-K
BC30	BC30TP1-K
BC40	BC40TP1-K
BC63	BC63TP1-K
CH21	CH21TP1-K
CH30	CH30TP1-K
CH32	CH32TP1-K
CH40	CH40TP1-K
CH63	CH63TP1-K
CH80	CH80TP1-K
CH1000	CH1000TP1-K
CT20	CT20TP1-K
CT40	CT40TP1-K
DNS404	DNS404TP1-K
DNS506	DNS506TP1-K
HAP210	HEP207TP1-K

COMPREHENSIVE SERVICE KITS	
For model number	Service kit part no.
HAS306	HAS30TP1-K
HAS506	HAS50TP1-K
HAS1006	HAS100TP1-K
HCC26	HCC26TP1-K
HCC34	HCC34TP1-K
HCC46	HCC46TP1-K
HCH40	HCH40TP1-K
HCH120	HCH120TP1-K
HDA 25 tonnes	HDA25TP1-K
HDA 50 tonnes	HDA50TP1-K
HDA 109 tonnes	HDA100TP1-K
HDA 152 tonnes	HDA150TP1-K
HDA 203 tonnes	HDA200TP1-K
HDA 326 tonnes	HDA300TP1-K
HDA 398 tonnes	HDA400TP1-K
HDA 520 tonnes	HDA500TP1-K
HEP12	HEP121TP1-K
HEP103	HEP103TP1-K
HEP207	HEP207TP1-K
HEP310	HEP310TP1-K
HEP517	HEP310TP1-K
HFG 50 tonnes	HFG50TP1-K
HFG 109 tonnes	HFG100TP1-K
HFG 152 tonnes	HFG150TP1-K
HFG 203 tonnes	HFG200TP1-K
HFG 326 tonnes	HFG300TP1-K
HFG 398 tonnes	HFG400TP1-K
HFG 520 tonnes	HFG500TP1-K
HFL 50 tonnes	HFL50TP1-K
HFL 109 tonnes	HFL100TP1-K
HFL 152 tonnes	HFL150TP1-K
HFL 260 tonnes	HFL250TP1-K
HFL 520 tonnes	HFL500TP1-K
HHP30	HHP30TP1-K
HHP50	HHP50TP1-K

Note: all service kits and spare parts detailed on pages 186 and 187 are latest model versions. Always check serial number of your product when ordering parts to ensure correct Hi-Force part supply.

REPLACEMENT PARTS

COMPREHENSIVE SERVICE KITS		COMPREHENSIVE SERVICE KITS		COMPREHENSIVE SERVICE KITS	
For model number	Service kit part no.	For model number	Service kit part no.	For model number	Service kit part no.
HHR 33 tonnes	HHR30TP1-K	HSS 4.5 tonnes	HSS5TP1-K	NS104	NS104TP1-K
HHR 61 tonnes	HHR60TP1-K	HSS 10 tonnes	HSS10TP2-K	NS110	NS110TP1-K
HHR 102 tonnes	HHR100TP1-K	HSS 14.5 tonnes	HSS15TP2-K	NS200	NS200TP1-K
HHR 152 tonnes	HHR150TP1-K	HSS 25 tonnes	HSS25TP2-K	NS206	NS206TP1-K
HHR 247 tonnes	HHR250TP2-K	HSS 29 tonnes	HSS30TP2-K	NS215	NS215TP1-K
HHS 11 tonnes	HHS10TP2-K	HSS 50 tonnes	HSS50TP2-K	PMV2	PMV2TP1-K
HHS 23 tonnes	HHS20TP2-K	HSS 73 tonnes	HSS75TP2-K	PMV3	PMV4TP1-K
HHS 33 tonnes	HHS30TP2-K	HSS 109 tonnes	HSS100TP2-K	PMV3	PMV4TP1-K
HHS 61 tonnes	HHS60TP2-K	HSWC19	HSWC19TP1-K	SC18X	SC18TP1-K
HHS 102 tonnes	HHS100TP2-K	HSWC28	HSWC28TP1-K	SC21	SC21TP1-K
HKP10	HKP10HTP1-K	HSWC44	HSWC44TP1-K	SC30	SC30TP1-K
HLS 10 tonnes	HLS10TP2-K	HTWP2140P	HTWP2140P-K	SC32	SC32TP1-K
HLS 20 tonnes	HLS20TP2-K	HTWP2141AR	HTWP2141/2-K	SC40	SC40TP1-K
HLS 32 tonnes	HLS30TP2-K	HTWP2142AR	HTWP2141/2-K	SC60	SC60TP1-K
HLS 50 tonnes	HLS50TP2-K	HTWP3140P	HTWP3140TP2-K	SCP103	SCP103TP1-K
HLS 109 tonnes	HLS100TP2-K	HTWP3141PA	HTWP3141/2TP2-K	SCP203	SCP203TP1-K
HLS 147 tonnes	HLS150TP2-K	HTWP3142PA	HTWP3141/2TP2-K	SCP303	SCP303TP1-K
HMJ10	HSS10TP2-K	HVL 10 tonnes	HVL10TP1-K	SJS10	SJS10TP1-K
HMJ25	HSS25TP2-K	HVL 20 tonnes	HVL20TP1-K	SKP7	SKP7TP1-K
HMNS104	HMNS104TP1-K	HVL 32 tonnes	HVL30TP1-K	STS1	STS1LCTP1-K
HMNS110	HMNS110TP1-K	HVL 50 tonnes	HVL50TP1-K	STS2	STS2LCTP1-K
HMNS200	HMNS200TP1-K	HVL 104 tonnes	HVL100TP1-K	STS3	STS3LCTP1-K
HP1 10	HP1 10TP2-K	HWRC1115	HWRC1115TP1-K	STS4	STS4LCTP1-K
HP145	HP1 10TP2-K	HWRC1125	HWRC1125TP1-K	STS5	STS5LCTP1-K
HP211	HP212TP1-K	HWRC1136	HWRC1136TP1-K	STS6	STS6LCTP1-K
HP212	HP212TP1-K	HWRC1145	HWRC1145TP1-K	STU1	STU1LCTP1-K
HP227	HP227TP2-K	IW13P	IW13PTP1-K	STU2	STU2LCTP1-K
HP232	HP232TP1-K	IW19P	IW19PTP1-K	STU3	STU3LCTP1-K
HP245	HP245TP1-K	IW25B	IW25BTP1-K	STU4	STU4LCTP1-K
HP252	HP252TP1-K	IW38B	IW38BTP1-K	STU5	STU5LCTP1-K
HP257	HP227TP2-K	JAH 20 tonnes	122059	STU6	STU6LCTP1-K
HP232D	HP232DTP1-K	JAH 30 tonnes	123059	STU7	STU7LCTP1-K
HP245D	HP245TP1-K	JAH 60 tonnes	126059	TWH27N	TWH27NTP2-K
HP252D	HP252DTP1-K	JAS 10 tonnes	JAS10TP1-K	TWH54N	TWH54NTP2-K
HP227FP	HP227FPTP2-K	JCH13	JCH13TP1-K	TWH120N	TWH120NTP2-K
HP227FPC	HP227FPTP2-K	JCH21	JCH21TP1-K	TWH210N	TWH210NTP2-K
HPC 10 tonnes	HPC10TP1-K	JCS10	JCS10TP1-K	TWH430N	TWH430NTP2-K
HPC 30 tonnes	HPC30TP1-K	JCS20	JCS20TP1-K	TWS17N	TWS17NTP2-K
HPC 50 tonnes	HPC50TP1-K	JCS30	JCS30TP1-K	TWS45N	TWS45NTP2-K
HPP210	HEP207TP1-K	JS4	JS4TP1-K	TWS100N	TWS100NTP2-K
HPS 4.5 tonnes	HPS5TP1-K	JSS35	JSS35TP1-K	TWS150N	TWS150NTP2-K
HPS 10 tonnes	HPS10TP2-K	JSS55	JSS55TP1-K	TWS370N	TWS370NTP2-K
HPS 20 tonnes	HPS20TP2-K	JSS106	JSS106TP1-K	XHP1500	XHP1500TP1-K
HPS 32 tonnes	HPS30TP2-K	JSS166	JSS166TP1-K	XHP2800	XHP2800TP1-K
HPS 50 tonnes	HPS50TP2-K	JSS207	JSS207TP1-K	XHP1500BTU	XHP1500TP1-K
HPS 73 tonnes	HPS75TP2-K	JSS327	JSS327TP1-K		
HPS 109 tonnes	HPS100TP2-K	JSS507	JSS507TP1-K		
HPS 147 tonnes	HPS150TP2-K	JSS1007	JSS1007TP1-K		

Hi-Force®

HYDRAULIC TOOLS

UK Head Office:

Hi-Force Limited
Prospect Way, Daventry, Northants, NN11 8PL, United Kingdom
Tel: +44 1327 301 000 - Fax: +44 1327 706 555
daventry@hi-force.com

Hi-Force Regional Offices:

Hi-Force Australia Pty. Ltd Rockingham Australia Tel: +61 8 9591 1288 Email: australia@hi-force.com	Hi-Force Caspian Baku Azerbaijan Tel: +994 12 447 4100 Email: baku@hi-force.com	Hi-Force LKL Rio das Ostras - RJ Brazil Tel: +55 2227 6011 09 Email: brasil@hi-force.com	Hi-Force Hydraulic Equipment (Shanghai) Ltd. Co. Shanghai, China Tel: +86 21 6697 3010 Email: china@hi-force.com
P.T. Hi-Force Indonesia Jakarta Selatan Indonesia Tel: +62 21 781 6860 Email: jakarta@hi-force.com	Hi-Force Hydraulics (Asia) S.B. Selangor Malaysia Tel: +603 5569 4209 Email: malaysia@hi-force.com	Hi-Force Nederland BV Strijen Netherlands Tel: +31 78 6745488 Email: holland@hi-force.com	Hi-Force Hydraulics (Pty) Ltd Midrand South Africa Tel: +27 11 314 0555 Email: south.africa@hi-force.com
	Hi-Force Hydraulics Abu Dhabi United Arab Emirates Tel: +971 2 551 3100 Email: abu.dhabi@hi-force.com	Hi-Force FZCO Dubai United Arab Emirates Tel: +971 4 815 0600 Email: dubai@hi-force.com	

Your authorised distributor:

www.hi-force.com