

# ET 229



Euromas II  
 Enclosure, ABS

Order no.: 63229000

**Colour of enclosure group**

Light grey, similar to RAL 7035; special colours on request


**Protection class**

IP 65/DIN EN 60529; higher ingress protection on request

**Enclosure material**

ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information

Scope of delivery: Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

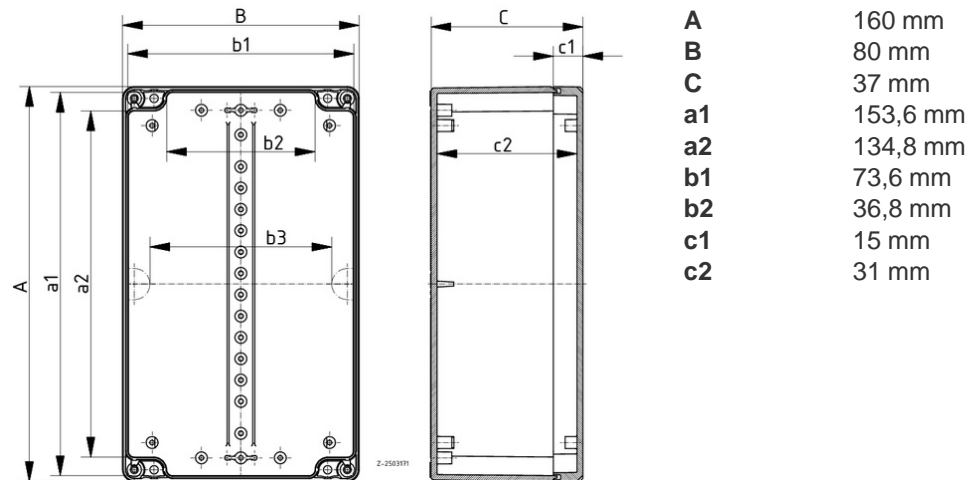

**Technical drawings**

Catalogue drawing in DXF format:

[63229000\\_ET-229.dxf](#) (735 KB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[63229000\\_ET-229-G.dxf](#) (497 KB)

Catalogue drawing in PDF format:

[63229000\\_ET-229.pdf](#) (75 KB)

**Chapter download**

[Euromas II\\_GB.pdf](#) (362 KB)

## Accessories



### Rubber feet, self-adhesive

22009000 [GF](#)

Polyurethane, 65-75 Shore Black



### Wall brackets, screw-on at rear

22010000 [EM-WL](#)



### Screw covers

22080000 [EM-SA](#)



### DIN rail acc. to DIN EN 60715 TH 15

22151501 [TS 15](#)

For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



### DIN rail acc. to DIN EN 60715 G 32

22321501 [TS 32](#)

For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



### DIN rail acc. to DIN EN 60715 TH 35

22351501 [TS 35](#)

For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..

\* = Available on request