



 

Pushing Performance

 
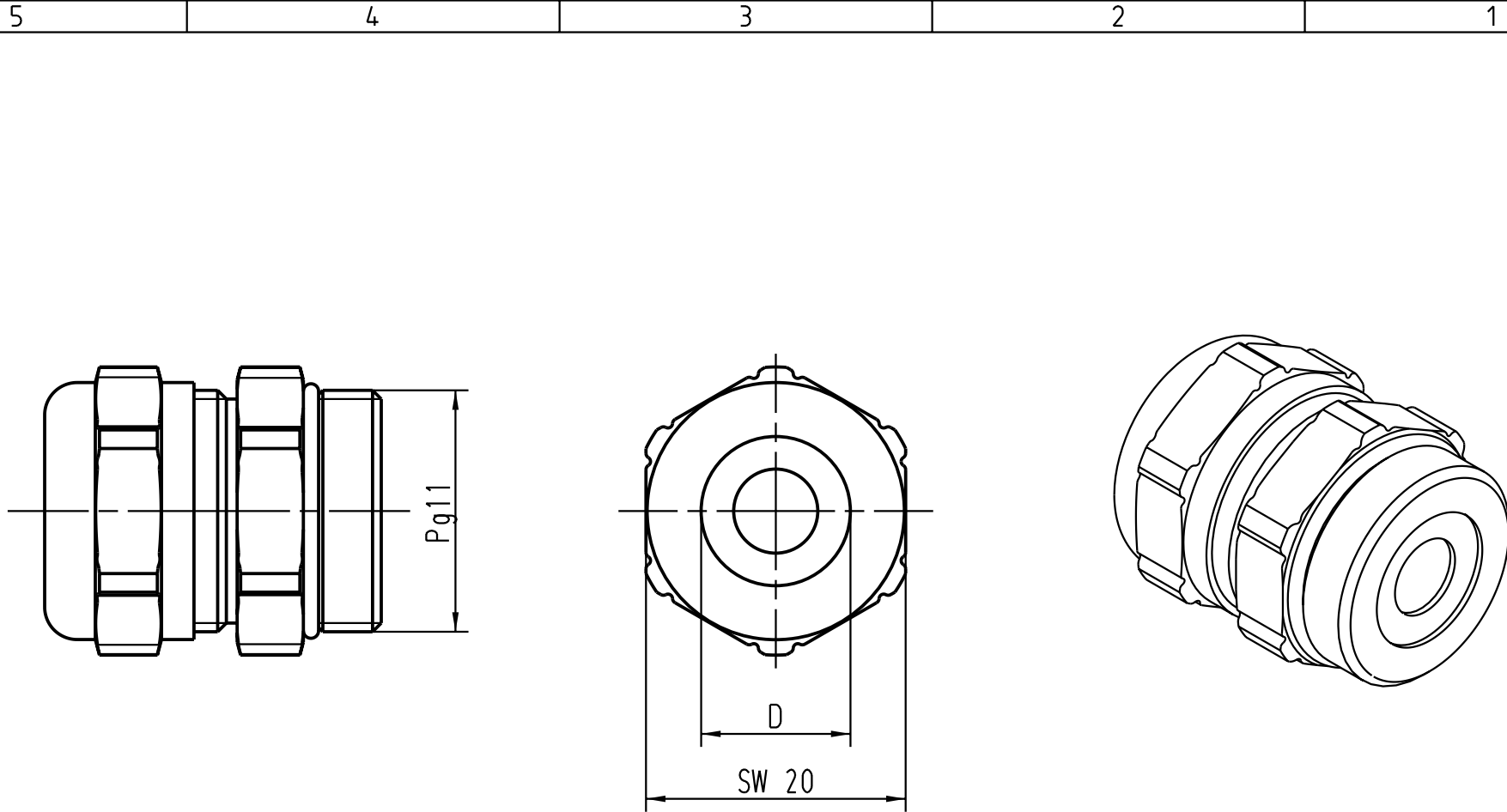
HARTING
Katalog-
Informations-
System
Version 11.1

Product details

09 00 000 5081

Universal cable protection

Cable entry protection	Pg 11
Cable protection type	Universal cable protection
Mat. of entry protection	Metal cable entry
Cable type	Cable entry f. round cable
Seal type	Universal cable protection
Cable diameter	6.5 - 9.5 mm
Colour of sealing	Black sealing
Protection level	IP 68
Application	browsing..  
Hoods/housings variants	Han® M
Used Housing	Cable to cable connection
RoHS compliant	Yes



All Dimensions in mm
Original Size DIN A 4

Techn. Character.

Nicht tolerierte Masse / Free size tolerances

09 00 000 5082

grün
green

7

10,5

09 00 000 5081

schwarz
black

6,5

9,5

09 00 000 5080

grau
grey

5

8

410278
25435

01.12.02
DY

HARTING Electric GmbH & Co. KG
D-32339 Espelkamp



	Dat.	Name	Massstab/Scale 2:1
Detail.	14.12.98	KR	
Insp.		SDT	
Stand.			

UNI Dichtverschraubung /
universal cable protection

Bestell Nr/ Part No

Farbe/ colour

D min.

D max.

Mod.

Dat.

Name

Sub. TB 09 00 000 508. v. 02.02.93

Blatt/ page
1/3