

Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035134
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	STICK
Lamp finish	FROSTED
Dimmable	No
Cap/Base	E14
Type	STICK
EAN code	5410288351346
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Efficacy (Rated) (lm/w)	56.25
Watt (Nominal) (W)	8
Equivalent watt (W)	42
Voltage (V)	220-240

Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

DATA TABLE

General data

Dry applications use only	Yes
Technology	Compact Fluorescent
Ordering number	0035134
Energy saving lamp	Yes
Average life (Rated) (h)	10000
Energy class	A
Average life (Nominal) (h)	10000
Lamp finish	FROSTED
Lamp shape	STICK
Dimmable	No
Cap/Base	E14
Type	STICK
EAN code	5410288351346
E-number FI	4940292
E-number SE	8357532
Product name	ML FAST-START 827 E14 8W SLV
Lamp mercury content (mg)	<2.5
Starting time (max) (s)	< 1.50 Sec
Warm-up time to 60% of full light (max) (s)	< 40 s
Control gear required	NO
IEC Reference	IEC 60968
IEC Reference 2	IEC 60969
IEC Reference 3	IEC 55015
ILCOS code	FBTH-08/27/1b-E14-44/112
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Lumen maintenance at end of nominal life (%)	= 75 %
Luminous flux (Rated) (lm)	450
Luminous flux (Nominal) (lm)	450
Chromaticity coordinate Y	0.420
Chromaticity coordinate X	0.463

Electrical data

kWh per 1000 hours burning time	8
Efficacy (Rated) (lm/w)	56.25
Watt (Nominal) (W)	8
Watt (Rated) (W)	8
Equivalent watt (W)	42
Voltage (V)	220-240
Current (A)	0.070
Lamp power factor	> 0.55

Physical data


Lamp Length (mm) - C/L	112
Lamp Diameter (mm) - D	44

Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

TECHNICAL DRAWINGS

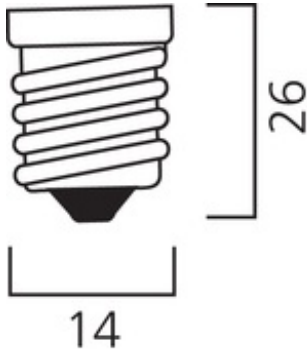

ENERGY LABEL

