
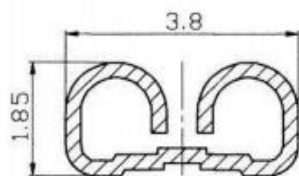
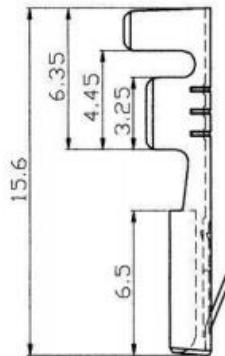


## Datasheet


### RS Crimp Receptacle, 3.3 x 0.8mm, 0.34 → 1.4 mm<sup>2</sup>, Tin Plated

RS Stock number [488-1257](#)


#### Dimensions (mm)

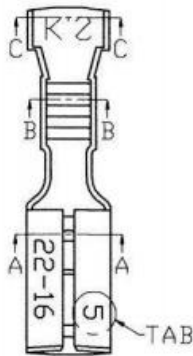

SECTION A-A  
SCALE 10/1

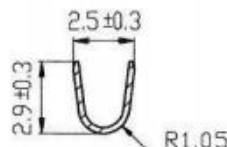

SECTION B-B

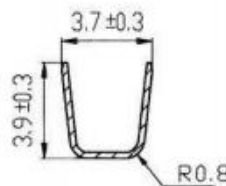

SECTION C-C

#### Specifications

- Thickness: 0.25mm
- Wire Range: 22-16 A.W.G
- Inspection Standard According to UL -310 Specifications
- Material: Brass