

Flat gasket - HC-B24-SG-RBK - 1407705

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 046356 777995
Weight per Piece (excluding packing)	7.5 g
Custom tariff number	40169300
Country of origin	Poland

Technical data

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

General

Material	NBR
Assembly instructions	For HC-EVO-B24.....BK housing

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402

Flat gasket - HC-B24-SG-RBK - 1407705

Classifications

ETIM

ETIM 3.0	EC000796
ETIM 4.0	EC000437
ETIM 5.0	EC001181

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Approvals

Approvals

Approvals

EAC

Ex Approvals


Approvals submitted

Approval details

EAC

Drawings

Dimensioned drawing

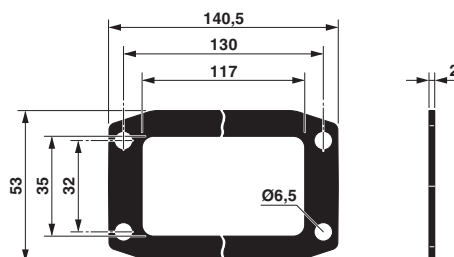

Dimensional drawing

