

MASTERColour CDM-TD

MASTERColour CDM-TD 70W/942 RX7s 1CT

Range of double-ended, compact, high-efficiency, discharge lamps with a stable colour over lifetime and a crisp, sparkling light

Product data

• General Characteristics

Cap-Base	RX7s
Bulb	T22 [T 22mm]
Bulb Finish	Clear
Burning Position	p45 [Parallel +/-45D or Horizontal(HOR)]
Life to 5% failures	9000 hr
Life to 10% failures	13000 hr
Life to 20% failures	15000 hr
Life to 50% failures	16000 hr

• Light Technical Characteristics

Colour Code	942 [CCT of 4200K]
Colour Rendering Index	92 Ra8
Colour Designation	Cool White
Colour Temperature	4200 K
Colour Temperature Technical	4060 K
Lamp Luminous Flux EM	5600 Lm
Lamp Luminous Efficacy EM	80 Lm/W
System Luminous Efficacy EL	72 Lm/W
Lumen Maintenance 2000h	85 %
Lumen Maintenance 5000h	70 %
Lumen Maintenance 10000h	60 %
Chromaticity Coordinate X	0.383 -
Chromaticity Coordinate Y	0.370 -

• Electrical Characteristics

System Power EM	87 W
System Power EL	83 W
Lamp Wattage	70 W
Lamp Wattage EM 25°C, Nominal	70.0 W
Lamp Wattage EM 25°C, Rated	71.0 W
Lamp Voltage	89 V
Lamp Current EM	0.98 A
Ignition Time	30 (max) s
Run-up time 90%	3 (max) min
Re-ignition Time [min]	15 (max) min
Dimmable	no

• Environmental Characteristics

Energy Efficiency Label (EEL)	A+
Mercury (Hg) Content	4.8 mg
Energy consumption kWh/1000h	78 kWh

• UV-related Characteristics

PET (NIOSH)	38 h.klx
Damage Factor D/fc	0.23 -

• Luminaire Design Requirements

Pinch Temperature	280 (max) C
Bulb Temperature	500 (max) C

PHILIPS

MASTERColour CDM-TD

Product Dimensions

Reference Length A	114.2 mm
Insertion Length B	117.6 (max) mm
Overall Length C	119.63 (max) mm
Diameter D	22 (max) mm
Light Center Length L	57.1 mm
Arc Length O	7 mm
Light Center Length L [inch]	2.25 in
Overall Length C [inch]	4.6875 (max) in
Diameter D [inch]	0.75 in

Product Data

Order code	200020 15
------------	-----------

 

Full product code	871150020002015
Full product name	MASTERColour CDM-TD 70W/942 RX7s 1CT
Order product name	MASTERC CDM-TD 70W/942 RX7s 1CT/12
Pieces per pack	1
Packing configuration	12
Packs per outerbox	12
Bar code on pack - EAN1	8711500200020
Bar code on outerbox - EAN3	8711500200037
Logistic code(s) - 12NC	928084705133
ILCOS code	MD/UB-70/942-H-RX7s-22/117.6
Net weight per piece	21.000 gr

Warnings and Safety

- Use only in totally enclosed luminaire, even during testing (IEC61167, IEC 62035, IEC60598)
- The luminaire must be able to contain hot lamp parts if the lamp ruptures

- Lamps may use electronic or electromagnetic control gear
- Control gear must include end-of-life protection (IEC61167, IEC 62035)

Dimensional drawing

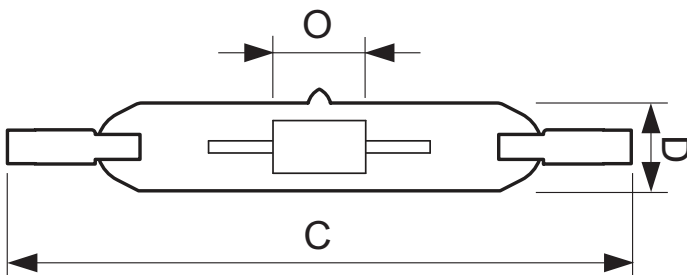


RX7s

MASTERColour CDM-TD 70W/942 RX7s 1CT

Product	C (Max)	D (Max)	O (Min)	O (Norm)	O (Max)
CDM-TD 70W/942 RX7s	119.63	22	-	7	-

Photometric data

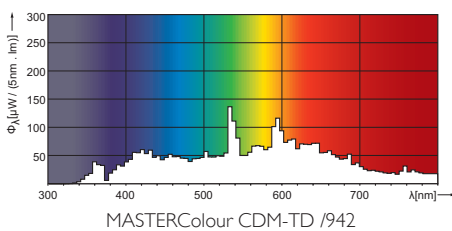



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, November 30
data subject to change