

ET 217



Euromas II
 Enclosure, ABS

Order no.: 63217000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request


Protection class

IP 65/DIN EN 60529; higher ingress protection on request

Enclosure material

ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information

Scope of delivery: Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

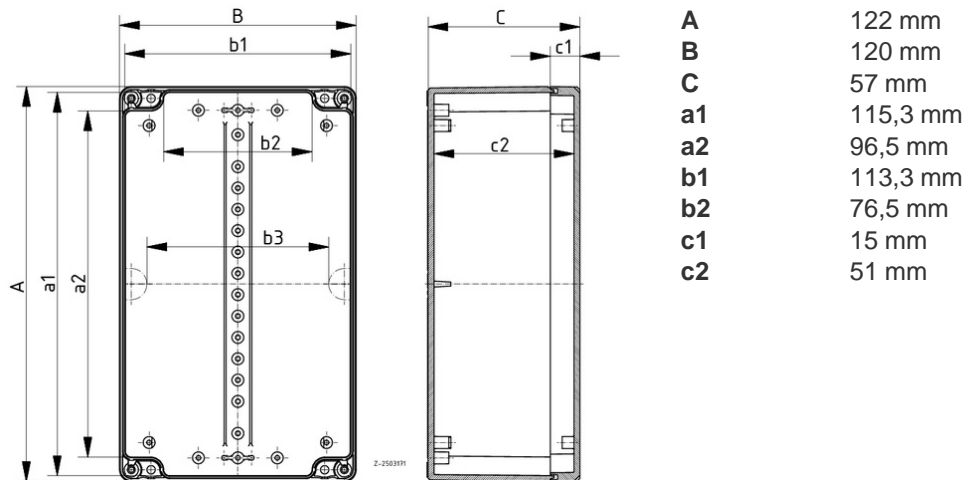

Technical drawings

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[63217000_ET-217-G.dxf](#) (453 KB)

Catalogue drawing in DXF format:

[63217000_ET-217.dxf](#) (822 KB)

Catalogue drawing in PDF format:

[63217000_ET-217.pdf](#) (85 KB)

Chapter download

[Euromas II_GB.pdf](#) (362 KB)

Accessories



Rubber feet, self-adhesive

22009000 [GF](#)

Polyurethane, 65-75 Shore Black



Wall brackets, screw-on at rear

22010000 [EM-WL](#)



Screw covers


22080000 [EM-SA](#)



Mounting panels, laminated paper

22000500 [M](#)

For EM/ET 217, EM/ET 227, M/T 217, M/T 227-228

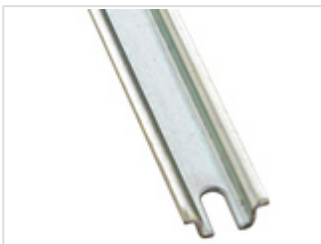

DIN rail acc. to DIN EN 60715 TH 15

22151101 [TS 15](#)

For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..



DIN rail acc. to DIN EN 60715 G 32

22321101 [TS 32](#)

For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..



DIN rail acc. to DIN EN 60715 TH 35

22351101 [TS 35](#)

For EM/ET 213, EM/ET 215-217, EM/ET 227, B



1408., B 1413..

* = Available on request