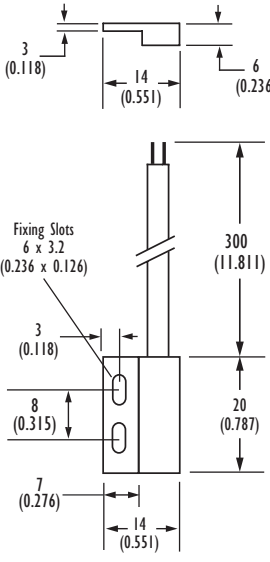


Part Number : MMPSB 130/30

Proximity Switch - Reed Switch based

Rectangular - Normally Closed Contacts - Suggested Magnet: MMPSM

Product Data Sheet

PICTURE	DIMENSIONS	Applications Include
	 Drawings not to scale All dimensions in mm(inches) nominal	● Position and limit sensing. ● Linear actuators . ● Security system switch. ● Door Switch. Options ● Also available in all Black. ● White economy version available. ● Left and Right hand version available. ● Custom cable lengths, strip lengths, cable types, terminations. ● If you do not see what you need, just ask, as there is a strong possibility we can do it !

✓RoHS Compliant

SPECIFICATION	
Contact Form / Style	Normally Closed
Switching Capacity (Resistive)	5 W/VA Max.
Switching Voltage	100 VAC Max.
Switching Current	0.5 A. Max.
Carry Current	1.0 A. Max.
Breakdown Voltage	200 VDC Min.
Contact Resistance	150 mOhms Max.
Switching Distance	8 mm Min.
Operating Temperature Range	-20°C +85°C
Storage temperature	-25°C +90°C
Case Material	Blue Nylon 66
Cable	2 x Round 0.14mm ² PVC covered Grey and insulated Brown / White

Did you know we also sell?



Rev. No.	Revision Note	Date	Signature
2	Datasheet Redesign	28-07-06	LG