


Verbatim LED GU10 6W 4000K 450lm 4000K Neutral White 470 LM DIM




- GU10 Socket
- 220-204V
- 40,000 hours Lifetime
- Dimmable
- 91% Energy Saving
- Luminous Flux: 470 lm
- Equivalent to 64W incandescent bulb

Product Number	52308
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	6.0
Wattage Equivalent (W)	64
Voltage (V)	220-204
Dimmable	yes
Power Factor	≥0.7
Operating Frequency (Hz)	50/60
Geometric Data	
Length (mm)	56
Diameter (in mm)	50
Weight (g)	55
Photometric Data	
Luminous Flux (lm)	470
Luminous Flux 90° Cone (lm)	450
CRI	80
CCT (K)	4000
Luminous Intensity (cd)	1170
Beam Angle (°)	35
Luminous Efficacy (lm/W)	78
Lifetime (hrs)	40,000
Switching Cycle	100,000

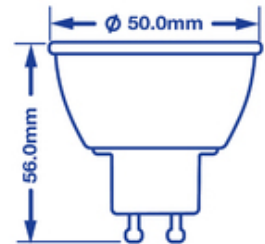


28/11/2014

Photometric Diagrams

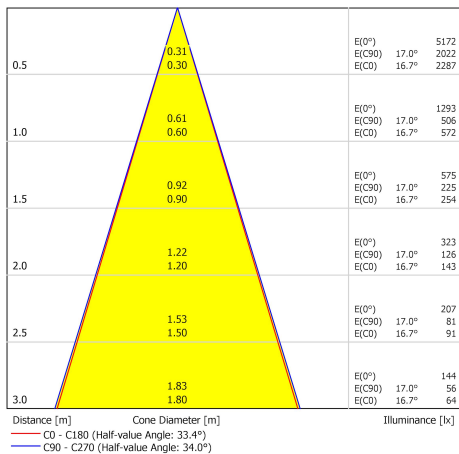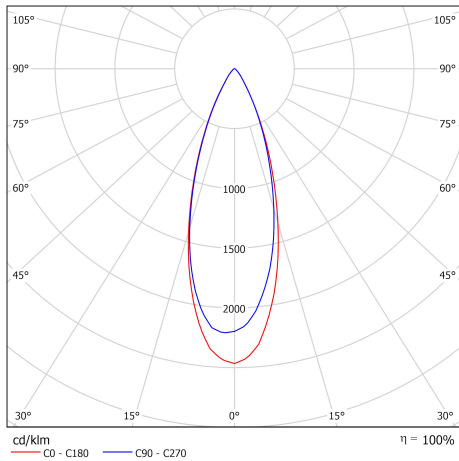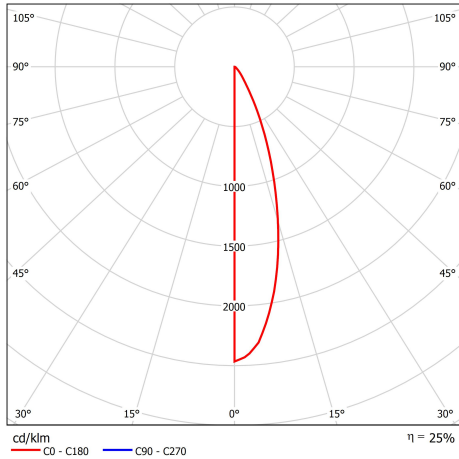

Energy Rating

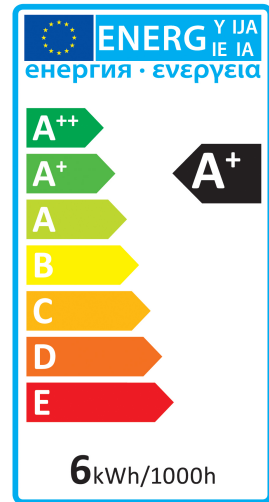

Technical Packaging Details

Barcode
023942523086

EAN 128
(02)00023942523086(37)10(91)814

EAN 14
50023942523081

Pack Dimensions(HxWxL)
H67 *W51*L51mm (mm)

MOQ
10

Carton Dimensions (HxWxL)
H97*W125 *L285mm (mm)

Cartons/Pallet
171

Layers/Pallet
9

Units/Pallet
1710

28/11/2014